


Grip ISO clip, single

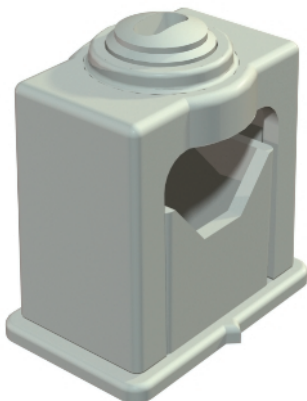


Solid cable fastening through clamping screws, with adhesive base, slot and for screwing to M6 thread.

Use the Impu-Fix ribbon conductor quick adhesive, type 509, to stick the polystyrene clips to masonry and concrete.

Type	Clamping range D mm	Colour	Pack. pcs	Weight kg/100 pcs.	Item No.
3040 LGR	6-16	Light grey	100	0,532	2105012
3041 LGR	16-24	Light grey	50	1,168	2105039
3042 LGR	24-34	Light grey	25	2,488	2105055

PS Polystyrene

Dimensions

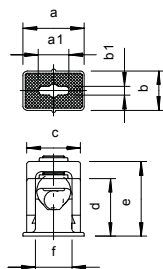

Type	Clamping range D mm	Dimension a1 mm	Dimension b1 mm	Dimension a mm	Dimension b mm	Dimension c mm	Dimension d mm	Dimension e mm	Dimension f mm
------	------------------------	--------------------	--------------------	-------------------	-------------------	-------------------	-------------------	-------------------	-------------------

3040 LGR	6-16	13,5	4	28	18	24,5	28	35	20
3041 LGR	16-24	20	4,2	35	22	37	36	44	31
3042 LGR	24-34	14	4,2	50	22	48	49	59	40