

SOM clip, single




With plastic screws, so corrosion-protected, with slot for fastening with wood screws or 5 mm knock-in anchors.

Type	Clamping range D mm	Colour	Pack. pcs	Weight kg/100 pcs.	Item No.
3079 LGR	5-14	Light grey	50	0,431	2124149
3080 LGR	6-17	Light grey	50	0,926	2124173
3081 LGR	15-25	Light grey	25	1,860	2124254
3082 LGR	22-34	Light grey	25	2,055	2124343

PS Polystyrene

Dimensions

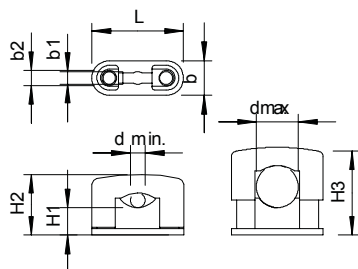

Type	Clamping range D mm	Dimension L mm	Dimension d min. mm	Dimension d max. mm	Dimension H1 mm	Dimension H2 mm	Dimension H3 mm	Dimension b mm	Dimension b1 mm	Bolt
3079 LGR	5-14	31	5	13	10,5	20	29	12	4,2	M5 x 14
3080 LGR	6-17	37	6	17	11	24,5	35,5	14	4	M6 x 18
3081 LGR	15-25	51	14	25	11,5	33	44	17	5	M8 x 23
3082 LGR	22-34	62	22	34	11	40	52	18	5,2	M8 x 23