

Technical data sheet

SOM clip, hardly flammable

Art.-Nr. 2124459



With plastic screws, so corrosion-protected, with slot for fastening with wood screws or 5 mm knock-in anchors.
Hardly inflammable.




UF Duroplast, Aminoplast, type 131.5

Master data

Item No.	2124459
Type	3083 LGR
Description 1	SOM clip
Dimension	32-45mm
Colour	Light grey
RAL number	7.035,00
Material	Duroplast, Aminoplast, type 131.5
Material symbol	UF
Smallest sales unit	20,00 pcs
Weight	5,84 kg/100 pcs.

Technical specifications

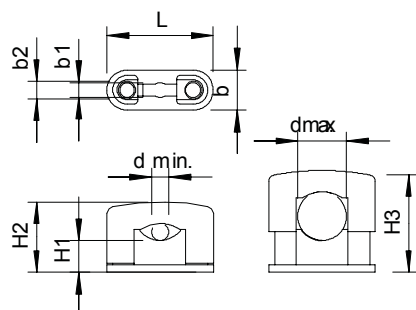

Dimension b	21,00 mm
Dimension b1	6,50 mm
Dimension d min.	32,00 mm
Dimension d max.	45,00 mm
Dimension H1	12,00 mm
Dimension H2	54,00 mm
Dimension H3	57,00 mm
Dimension L	77,00 mm
Number of cables/pipes	1,00
Version	Closed
Fastening type	Screw hole
Suitable in fire protection area	☒
Halogen-free	☒
Plastic coated	☒
Bolt	M8 x 40
Clamping range D	32,00 - 45,00 mm
UV-resistant	☒