

Technical data sheet

GRIP "M" 15

Art.-Nr. 2207028



Metal cable tidy for high mechanical stability, even in case of fire. Suitable for safe mounting above fire protection ceilings. Also approved as a cable-specific variant for the maintenance of electrical function to DIN 4102 part 12. For wall and ceiling mounting. Lock can be opened without tools. Detailed information on the approved routing variants can be found in the appropriate testing documentation.




St	Steel
FS	Strip-galvanised

Master data

Item No.	2207028
Type	2031 M 15 FS
Description 1	Grip collecting clamp
Dimension	15x NYM3x1,5
Material	Steel
Material symbol	St
Surface finish	Strip-galvanised
Interface to DIN	DIN EN 10346
Interface symbol	FS
Smallest sales unit	50,00 pcs
Weight	3,70 kg/100 pcs.

Technical specifications

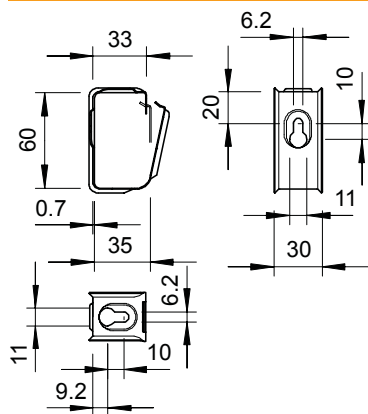

No. of conductors NYM 3 x 1.5	15,00
Flame-resistant version	☒
Suitable for function maintenance	☒
Halogen-free	☒
With anchor	☒