

# Technical data sheet

## GRIP "M" 30

Art.-Nr. 2207036



Metal cable tidy for high mechanical stability, even in case of fire. Suitable for safe mounting above fire protection ceilings. Also approved as a cable-specific variant for the maintenance of electrical function to DIN 4102 part 12. For wall and ceiling mounting. Lock can be opened without tools. Detailed information on the approved routing variants can be found in the appropriate testing documentation.




|           |                  |
|-----------|------------------|
| <b>St</b> | Steel            |
| <b>FS</b> | Strip-galvanised |

### Master data

|                     |                       |
|---------------------|-----------------------|
| Item No.            | 2207036               |
| Type                | 2031 M 30 FS          |
| Description 1       | Grip collecting clamp |
| Dimension           | 30x NYM3x1,5          |
| Material            | Steel                 |
| Material symbol     | St                    |
| Surface finish      | Strip-galvanised      |
| Interface to DIN    | DIN EN 10346          |
| Interface symbol    | FS                    |
| Smallest sales unit | 25,00 pcs             |
| Weight              | 6,20 kg/100 pcs.      |

### Technical specifications

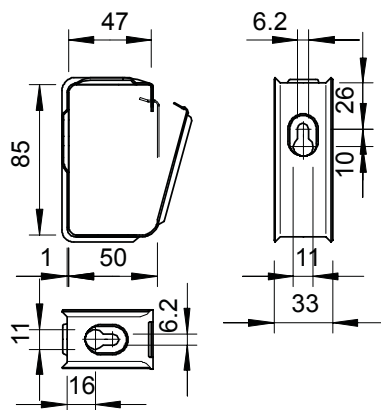

|                                   |                                     |
|-----------------------------------|-------------------------------------|
| No. of conductors NYM 3 x 1.5     | 30,00                               |
| Flame-resistant version           | <input checked="" type="checkbox"/> |
| Suitable for function maintenance | <input checked="" type="checkbox"/> |
| Halogen-free                      | <input checked="" type="checkbox"/> |
| With anchor                       | <input checked="" type="checkbox"/> |