


Technical data sheet

Pressure clip for 8 cables

Art.-Nr. 2205017

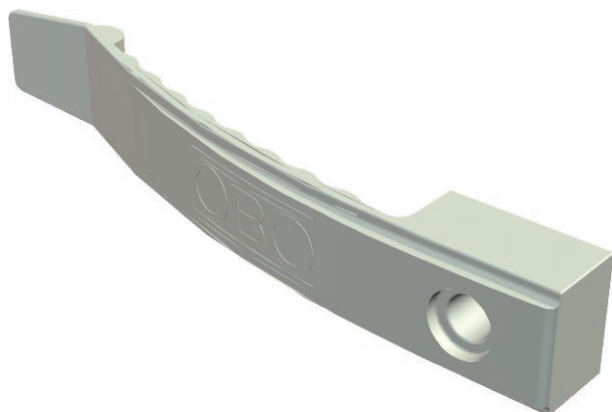

Standard version for general use, e.g. on intermediate ceilings and partition walls.
Clamping height 9 mm – with spacer 13 mm.
Fastening hole: 6 mm Ø.




PA Polyamide

Product additional text for information	Stone grey version: flame-resistant version, specially for use in suspended ceilings. Thermoplastic Polyester, stone grey RAL 7030, flame-resistant to VDE 0471/DIN IEC 695 Part 2-1, test temperature 960 °C, respectively V-0 to UL 94, halogen-free. Clamping height 9 mm – with spacer 13 mm. Fastening hole: 6 mm Ø.
Product additional text 1	2032 for max. 8 cables NYM 3 x 1.5 mm ²

Master data

Item No.	2205017
Type	2032
Description 1	Pressure clip
Dimension	1x8 NYM3x1,5
Colour	Light grey
RAL number	7.035,00
Material	Polyamide
Material symbol	PA
Smallest sales unit	50,00 pcs
Weight	1,37 kg/100 pcs.

Technical specifications

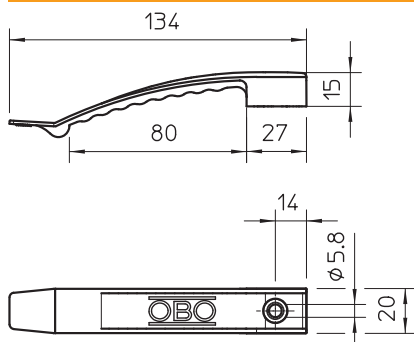

No. of conductors NYM 3 x 1.5	8,00
Flame-resistant version	☒
Suitable for function maintenance	☒
Halogen-free	☒
With anchor	☒