

Suction plate (round)

SPU 160 NBR-55 G1/2-IG

Part no.:10.01.01.01116


<https://www.schmalz.com/10.01.01.01116>



Technical Data

Attribute	Value
Suction force (-600mbar)	1,090 N
Suction force d2	600 N
Volume	142 cm ³
Curve radius (min) (convex)	350 mm
Hose diameter (empf.) d	12 mm
Size	160
Suction cup material	Nitrile rubber NBR
Material hardness [Shore A]	55 Shore A
Weight	400 g
Number of folds	0
Product family	SPU

Spare Parts

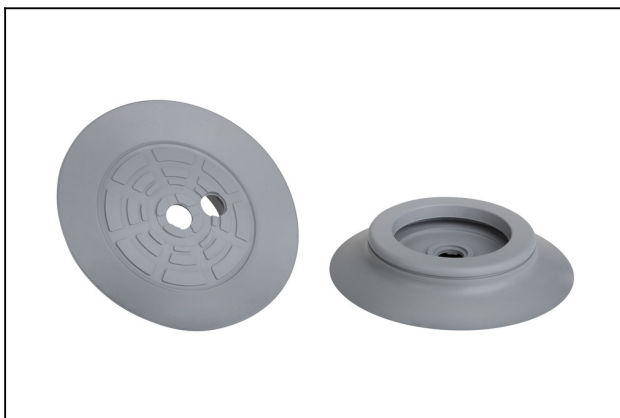

DR-SPU 160 NBR-55

Part no.10.01.01.01111

Sealing ring for suction plate SPU

Size: 160

Suction cup material:

Nitrile rubber NBR

Material hardness: 55 °Sh

Suction plate (round)

SPU 160 NBR-55 G1/2-IG

Part no.:10.01.01.01116

<https://www.schmalz.com/10.01.01.01116>



Accessories



SU 160

Part no.10.01.01.12438

Cover for suction cup

Size: 160

Clamping range: 150.0 ... 180.0 mm

Temperature resistance: 80 °C