

Spring plunger

FSTE G1/8-AG 15 VG


Part no.:10.01.02.00605

<https://www.schmalz.com/10.01.02.00605>



Homepage > Vacuum Technology for Automation > Vacuum Components > Mounting Elements > Spring plunger > Spring Plungers FSTE > FSTE G1/8-AG 15 VG

Spring plunger with damping and height compensation

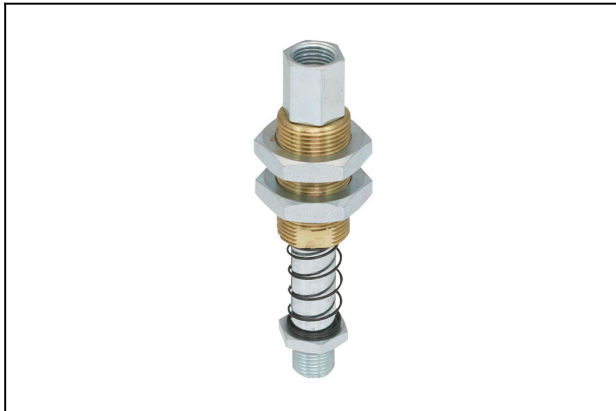


Suction cup connection: G1/8"-M

Vacuum connection: G1/8"-F

Spring stroke Z: 15 mm

Shape: With rotation lock

Design Data

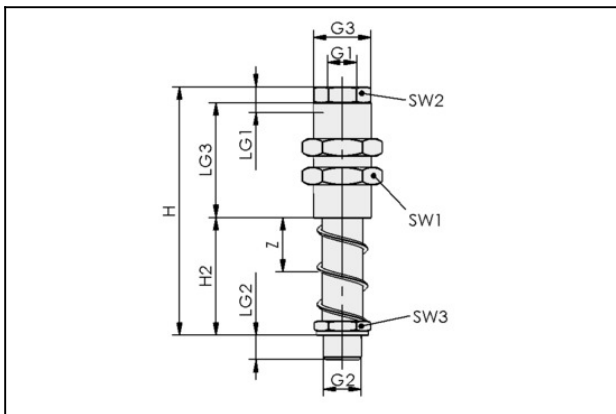

Attribute	Value
-----------	-------

G1	G1/8"-IG
----	----------

G2	G1/8"-M
----	---------

G3	M16x1-M
----	---------

H	72.5 mm
---	---------

H2	28.5 mm
----	---------

LG1	8 mm
-----	------

LG2	6.5 mm
-----	--------

LG3	30 mm
-----	-------

SW1	22 mm
-----	-------

SW2	12 mm
-----	-------

SW3	14 mm
-----	-------

Z (Stroke)	15 mm
------------	-------

Spring plunger FSTE G1/8-AG 15 VG

Part no.:10.01.02.00605

<https://www.schmalz.com/10.01.02.00605>




Technical Data

Attribute	Value
Spring rate	0.221 N/mm
Spring pretension	3.53 N
Spring force, center	5.19 N
Vertical load	3,700 N
Horizontal load	385 N
Weight	80 g
Operating temperature	0 ... 80 °C

Note: Spring force: Referred to 50% of operating stroke Static loading: Maximum static loading
Horizontal stress: The specification of the horizontal stress refers to the lower edge of the plunger with extended spring. It is a maximum static stress and it impairs the spring compression and extension in horizontal position

Spare Parts

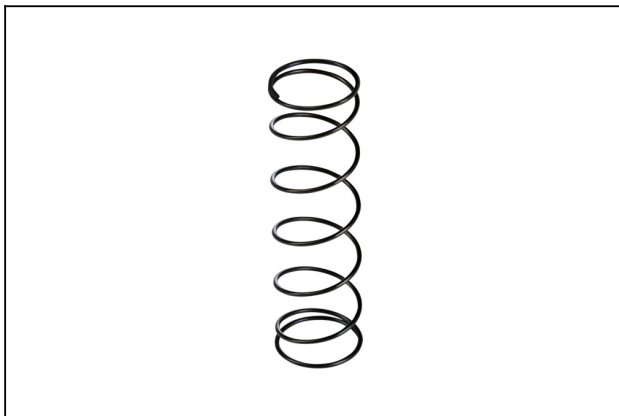

DRUCK-FED 0.63x10.97 40 0.221

Part no.20.08.02.00056

Pressure spring

Wire size: 0.63 mm

Diameter: 10.97 mm

Length L: 40 mm

Spring rate: 0.221 N/mm

Accessories

Spring plunger FSTE G1/8-AG 15 VG

Part no.:10.01.02.00605

<https://www.schmalz.com/10.01.02.00605>



KGL G1/8-IG G1/8-AG A2

Part no.10.01.03.00109


Suction cup mounting with joint for adaptation to sloping surfaces

Thread G1: G1/8"-F

Thread G2: G1/8"-M

Height H: 26.5 mm

Material: Aust. Stainless steel

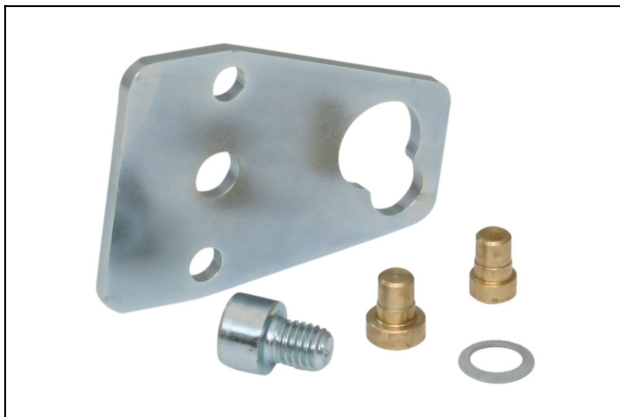

HTR-STA 47 1N D10/16 FL

Part no.10.08.03.00085

Holder for flexible mounting of suction cups/spring plungers on sections

Length L: 47 mm

Cross-beam connection: Sliding block

Suction cup or spring plunger conn.:

Contour D10 and D16

Shape: flat



HTR-STs 30x30 D10/16 WI

Part no.10.08.03.00088

Holder for flexible mounting of suction cups/spring plungers on square tubes

Cross-beam connection: 30x30

Suction cup or spring plunger conn.:

Contour D10 and D16

Shape: angled

Spring plunger FSTE G1/8-AG 15 VG

Part no.:10.01.02.00605

<https://www.schmalz.com/10.01.02.00605>



HTR-ST 40x40 D10/16 WI

Part no.10.08.03.00089


Holder for flexible mounting of suction cups/spring plungers on square tubes

Cross-beam connection: 40x40

Suction cup or spring plunger conn.:

Contour D10 and D16

Shape: angled

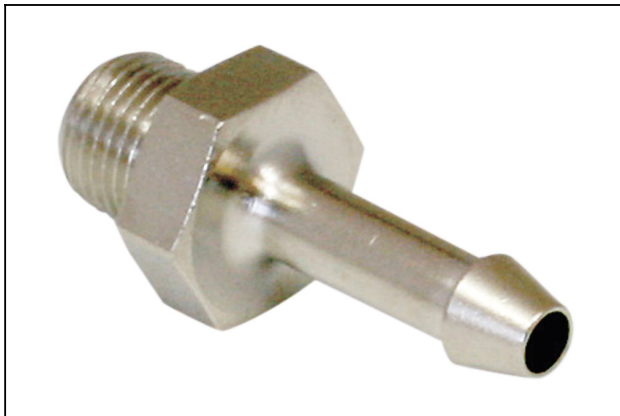

ST G1/8-AG 4 MS-V

Part no.10.08.03.00153


Hose sleeve

Thread G1: G1/8"-M

Internal hose diameter: 4 mm

Material: Brass

Surface: nickel plated

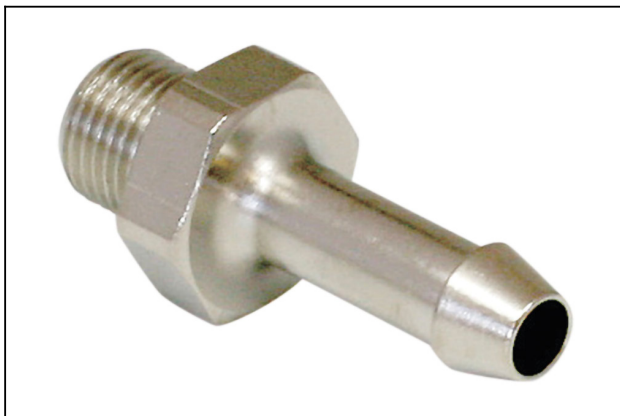

ST G1/8-AG 6 MS-V

Part no.10.08.03.00154

Hose sleeve

Thread G1: G1/8"-M

Internal hose diameter: 6 mm

Material: Brass

Surface: nickel plated

Spring plunger FSTE G1/8-AG 15 VG

Part no.:10.01.02.00605

<https://www.schmalz.com/10.01.02.00605>



ST G1/8-AG 9 MS-V

Part no.10.08.03.00155

Hose sleeve

Thread G1: G1/8"-M

Internal hose diameter: 9 mm

Material: Brass

Surface: nickel plated



STV-GE G1/8-AG 4

Part no.10.08.02.00202

Push-in Fitting, straight

Thread G1: G1/8"-M

External hose diameter: 4 mm

Material: Brass

Surface: nickel plated

Ambient temperature: -20 ... 80 °C



STV-GE G1/8-AG 6

Part no.10.08.02.00204

Push-in Fitting, straight

Thread G1: G1/8"-M

External hose diameter: 6 mm

Material: Brass

Surface: nickel plated

Ambient temperature: -20 ... 80 °C

Spring plunger FSTE G1/8-AG 15 VG

Part no.:10.01.02.00605

<https://www.schmalz.com/10.01.02.00605>



STV-GE G1/8-AG 8

Part no.10.08.02.00206

Push-in Fitting, straight

Thread G1: G1/8"-M

External hose diameter: 8 mm

Material: Brass

Surface: nickel plated



STV-W G1/8-AG 4

Part no.10.08.02.00156

Push-in Fitting, swivelling elbow

Thread G1: G1/8"-M

External hose diameter: 4 mm

Material: Brass, nickel-plated

Ambient temperature: -20 ... 80 °C



STV-W G1/8-AG 6

Part no.10.08.02.00158

Push-in Fitting, swivelling elbow

Thread G1: G1/8"-M

External hose diameter: 6 mm

Material: Brass, nickel-plated

Ambient temperature: -20 ... 80 °C

Spring plunger FSTE G1/8-AG 15 VG

Part no.:10.01.02.00605

<https://www.schmalz.com/10.01.02.00605>



STV-W G1/8-AG 8

Part no.10.08.02.00160

Push-in Fitting, swivelling elbow

Thread G1: G1/8"-M

External hose diameter: 8 mm

Material: Brass, nickel-plated

Ambient temperature: -20 ... 80 °C



STV-GE G1/8-AG 6 HT

Part no.10.08.02.00389

Push-in Fitting, straight

Thread G1: G1/8"-M

External hose diameter: 6 mm

Material: Brass

Surface: nickel plated

Ambient temperature: -50 ... 200 °C

Type: HT



STV-W G1/8-AG 6

Part no.10.08.02.00288

Push-in Fitting, swivelling elbow

Thread G1: G1/8"-M

External hose diameter: 6 mm

Material: Plastic

Spring plunger FSTE G1/8-AG 15 VG

Part no.:10.01.02.00605

<https://www.schmalz.com/10.01.02.00605>



STV-W G1/8-AG 6 HT

Part no.10.08.02.00391

Push-in Fitting, swivelling elbow

Thread G1: G1/8"-M

External hose diameter: 6 mm

Material: Brass

Surface: nickel plated

Ambient temperature: -50 ... 200 °C

Type: HT



STV-WF G1/8-AG 4

Part no.10.08.02.00166

Push-in Fitting, swivelling and lockable

Thread G1: G1/8"-M

External hose diameter: 4 mm

Material: Brass, nickel-plated

Ambient temperature: -10 ... 70 °C



STV-WF G1/8-AG 6

Part no.10.08.02.00168

Push-in Fitting, swivelling and lockable

Thread G1: G1/8"-M

External hose diameter: 6 mm

Material: Brass, nickel-plated

Ambient temperature: -10 ... 70 °C

Spring plunger FSTE G1/8-AG 15 VG

Part no.:10.01.02.00605

<https://www.schmalz.com/10.01.02.00605>



STV-WF G1/8-AG 8

Part no.10.08.02.00170

Push-in Fitting, swivelling and lockable

Thread G1: G1/8"-M

External hose diameter: 8 mm

Material: Brass, nickel-plated

Ambient temperature: -10 ... 70 °C



STV-WF G1/8-AG 10

Part no.10.08.02.00257

Push-in Fitting, swivelling and lockable

Thread G1: G1/8"-M

External hose diameter: 10 mm

Material: Brass, nickel-plated

Ambient temperature: -10 ... 70 °C



STV-T G1/8-AG 4

Part no.10.09.02.00039

Push-in Fitting, T

Thread G1: G1/8"-M

External hose diameter: 4 mm

Length L: 32.5 mm

Material: Brass

Surface: nickel plated

Spring plunger FSTE G1/8-AG 15 VG

Part no.:10.01.02.00605

<https://www.schmalz.com/10.01.02.00605>



STV-T G1/8-AG 6

Part no.10.09.02.00040

Push-in Fitting, T

Thread G1: G1/8"-M

External hose diameter: 6 mm

Length L: 41.5 mm

Material: Brass

Surface: nickel plated



STV-T G1/8-AG 8

Part no.10.09.02.00041

Push-in Fitting, T

Thread G1: G1/8"-M

External hose diameter: 8 mm

Length L: 48.7 mm

Material: Brass

Surface: nickel plated