

Bell suction cup (round)

SPB1 30 ED-65 G1/8-IG

Part no.:10.01.06.03497

<https://www.schmalz.com/10.01.06.03497>



Homepage > Vacuum Technology for Automation > Vacuum Components > Vacuum Suction Cups > Suction Cups for Packaging > Bellows

Suction Cups SPB1 (1.5 Folds) > SPB1 30 ED-65 G1/8-IG

Bellows suction cup (round) for very uneven workpieces



Size: 30


Suction cup material: Elastodur

Material hardness: 65 °Sh

Thread G1: G1/8"-F

Number of folds: 1.5

Design Data

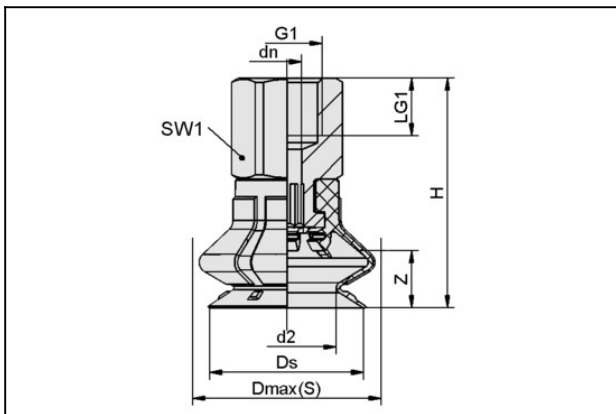

Attribute	Value
-----------	-------

d2	20 mm
----	-------

dn	4.1 mm
----	--------

Dmax(S)	36.7 mm
---------	---------

Ds	31.4 mm
----	---------

G1	G1/8"-IG
----	----------

H	37 mm
---	-------

LG1	8 mm
-----	------

SW1	14 mm
-----	-------

Z (Stroke)	13 mm
------------	-------

Technical Data

[Contact to Schmalz](#)

Schmalz Sp.z.o.o. | Kobaltowa 4, 62-002 Złotniki, Polen | +48 22 460 49 70 | schmalz@schmalz.pl

Page 1 of 3

Bell suction cup (round)

SPB1 30 ED-65 G1/8-IG


Part no.:10.01.06.03497

<https://www.schmalz.com/10.01.06.03497>



Attribute	Value
Suction force (-600mbar)	20.7 N
Pull-off force	30.6 N
Lateral force	15.5 N
Volume	7.993 cm ³
Curve radius (min) (convex)	35 mm
Hose diameter (empf.) d	6 mm
Size	30
Number of folds	1.5
Suction cup material	Elastodur
Material hardness [Shore A]	65 Shore A
Weight	8.9 g
Product family	SPB1

Spare Parts

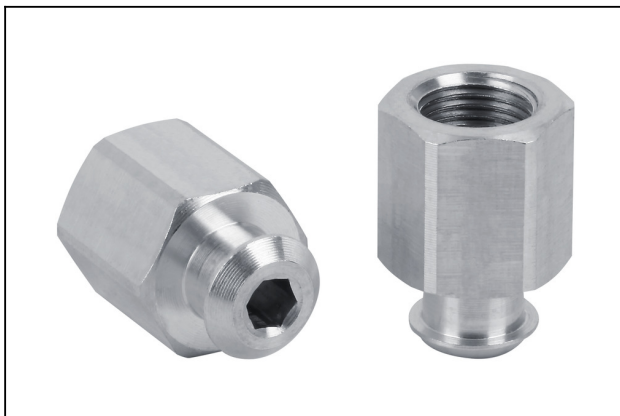

SC 040 G1/8-IG

Part no.10.01.06.02482

Connection element for suction cup "SchmalzConnector"

Connection geometry: 040

Vacuum connection: G1/8"-F

Overall length: 20.7 mm

Fitting length: 14 mm

Nominal diameter dn: 4.1 mm

Bell suction cup (round)

SPB1 30 ED-65 G1/8-IG

Part no.:10.01.06.03497

<https://www.schmalz.com/10.01.06.03497>



SPB1 30 ED-65 SC040

Part no.10.01.06.02454

Bellows suction cup (round) with 1.5 corr. for dynamic handling of cardboard and rigid packaging

Size: 30

Suction cup material: Elastodur

Material hardness: 65 °Sh

Number of folds: 1.5

Accessories



SIEB 11x1 MS-A2 280 0.28/0.16

Part no.10.07.01.00309

Screen

External diameter D: 11 mm

Length L: 1 mm

Material: Brass / Stainless steel

Filter pore size: 280 µm

Mesh: 0.28 mm

Wire size: 0.16 mm



SPI 26 PA SPB1-30

Part no.10.01.06.03386

Suction cup insert for preventing deformation of sensitive workpieces

Size: 26

Material: Polyamide

Application: SPB1-30