

Vacuum block

VCBL-K2 140x115x100


Part no.:10.01.12.00445

<https://www.schmalz.com/10.01.12.00445>



Homepage > Vacuum Clamping Technology > Clamping Equipment for Woodworking > Clamping Equipment for 2-Circuit Systems > Vacuum Blocks VCBL-K2 > VCBL-K2 140x115x100


Vacuum block for Schmalz 2-circuit console

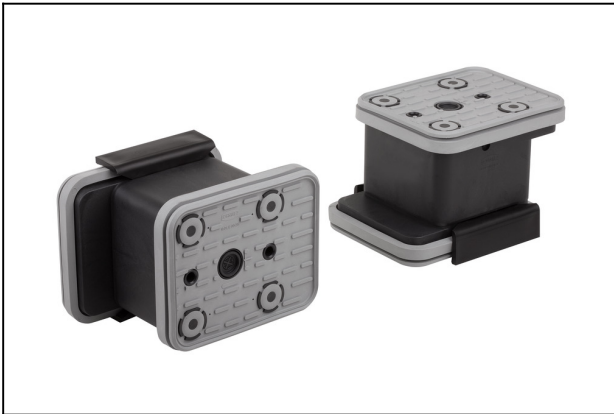

Dimensions (LxW): 140 x 115 mm

Height H: 100 mm

Design Data

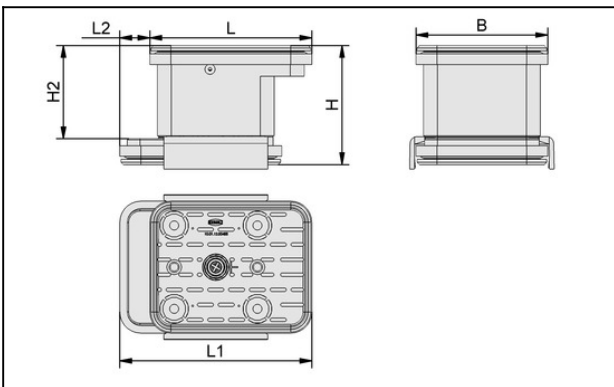

Attribute	Value
-----------	-------

B	115 mm
---	--------

H	100 mm
---	--------

H2	74.8 mm
----	---------

L	140 mm
---	--------

L1	166 mm
----	--------

L2	26 mm
----	-------

Technical Data

Attribute	Value
-----------	-------

Weight	0.77 kg
--------	---------

Vacuum block


VCBL-K2 140x115x100

Part no.:10.01.12.00445

<https://www.schmalz.com/10.01.12.00445>



Spare Parts

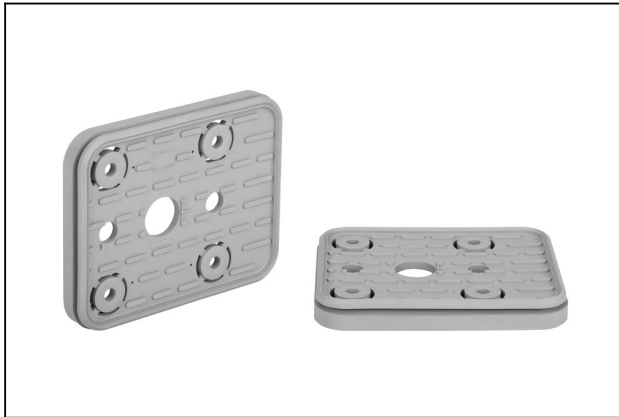


VCSP-O 140x115x16.5

Part no.10.01.12.00488

Suction-Plate for vacuum block, (top)

Dimensions (LxW): 140 x 115 mm

Height H: 16.5 mm

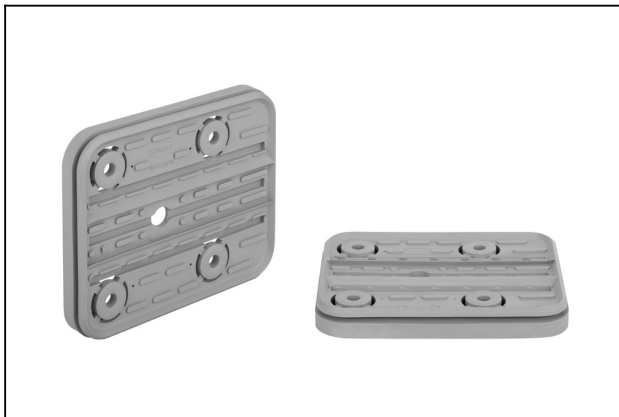

VCSP-U 140x115x16.5 VCBL-K2


Part no.10.01.12.00798

Suction plate for vacuum block bottom

Dimensions (LxW): 140 x 115 mm

Height H: 16.5 mm

for: Vacuum block VCBL-K2

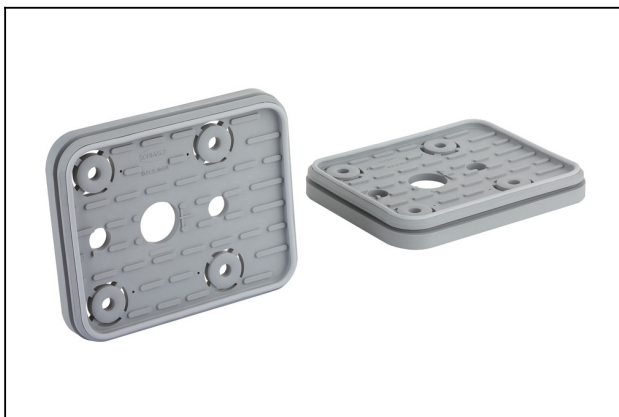

VCSP-O 140x115x18.5 MOS

Part no.10.01.12.03507

Suction-Plate for vacuum block, (top)

Dimensions (LxW): 140 x 115 mm

Height H: 18.5 mm

with: Sealing lip with MOS

Accessories

Contact to Schmalz


Schmalz Sp.z.o.o. | Kobaltowa 4, 62-002 Złotniki, Polen | +48 22 460 49 70 | schmalz@schmalz.pl

Vacuum block

VCBL-K2 140x115x100

Part no.:10.01.12.00445

<https://www.schmalz.com/10.01.12.00445>

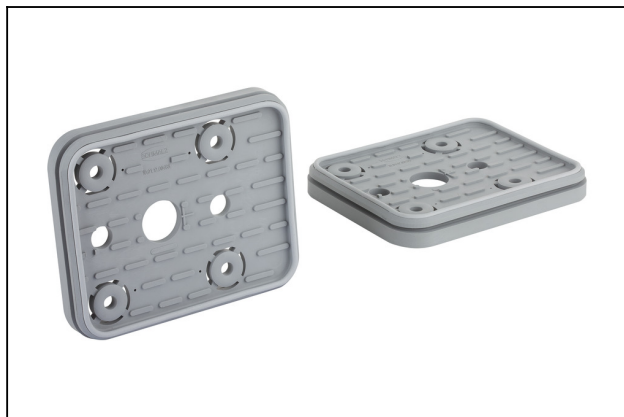

VCSP-O 140x115x18.5 MOS

Part no.10.01.12.03507

Suction-Plate for vacuum block, (top)

Dimensions (LxW): 140 x 115 mm

Height H: 18.5 mm

with: Sealing lip with MOS