

Multi-Clamp suction plate

VC-M-SP 160x160x30

Part no.:10.01.12.01836

<https://www.schmalz.com/10.01.12.01836>



Homepage > Vacuum Clamping Technology > Clamping Equipment for Woodworking > Clamping Equipment for Manual Work > Multi-Clamp


Suction Plates VC-M-SP / VC-M-SPV > VC-M-SP 160x160x30

Multi-Clamp - Suction plate with integrated vacuum generation



Length L: 160 mm
Width B: 160 mm
Height H: 30 mm
Air consumption: 2.88 m³/h
Air consumption: 48 l/min
Suction rate: 2.3 m³/h

Design Data

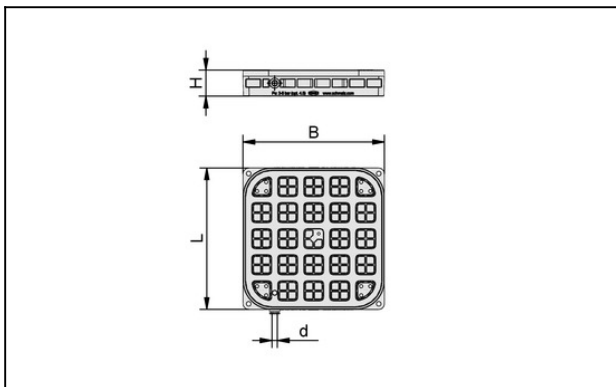

Attribute	Value
B	160 mm
d	6 mm
H	30 mm
L	160 mm

Technical Data

Attribute	Value
Weight	0.875 kg

Multi-Clamp suction plate

VC-M-SP 160x160x30

Part no.:10.01.12.01836

<https://www.schmalz.com/10.01.12.01836>

Accessories



VC-M-B 170x165x209

Part no.10.01.12.01854

Turning and slewing device Base

Length L: 170 mm

Width B: 165 mm

Height H: 209 mm