

Vacuum block

VCBL-G-K1 140x115x30

Part no.:10.01.12.03766

<https://www.schmalz.com/10.01.12.03766>



Homepage > Vacuum Clamping Technology > Clamping Equipment for Woodworking > Clamping Equipment for Nesting Table Systems >

Vacuum Blocks VCBL-G-K1 > VCBL-G-K1 140x115x30

Vacuum block for smooth table with hose connection




for: 2-circuit vacuum system

Dimensions (LxW): 140 x 115 mm

Height H: 30 mm

Internal hose diameter (recom.): 4 mm

Design Data

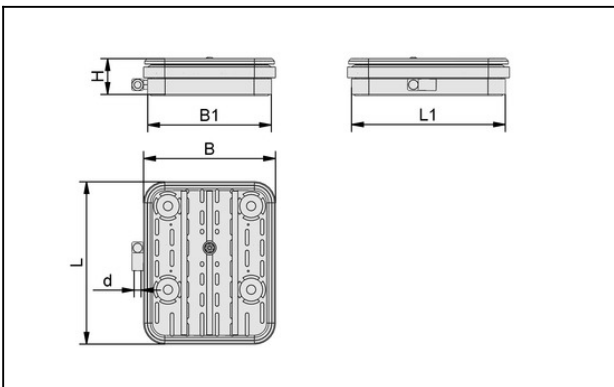

Attribute	Value
-----------	-------

B	114 mm
---	--------

B1	107 mm
----	--------

d	6 mm
---	------

H	30 mm
---	-------

L	140 mm
---	--------

L1	133 mm
----	--------

Spare Parts

Vacuum block

VCBL-G-K1 140x115x30

Part no.:10.01.12.03766

<https://www.schmalz.com/10.01.12.03766>



STV-W M5-AG 6

Part no.10.08.02.00235

Push-in Fitting, swivelling elbow

Thread G1: M5-M

External hose diameter: 6 mm

Material: Brass, nickel-plated

Ambient temperature: -20 ... 80 °C



STV-W M5-AG 4

Part no.10.08.02.00155


Push-in Fitting, swivelling elbow

Thread G1: M5-M

External hose diameter: 4 mm

Material: Brass, nickel-plated

Ambient temperature: -20 ... 80 °C

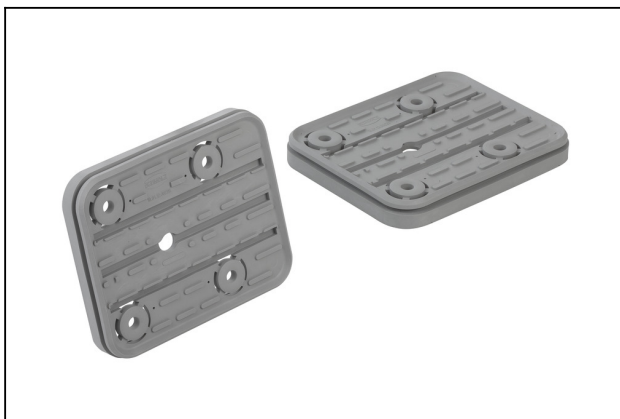

VCSP-U 140x115x16.5 VCBL-K1

Part no.10.01.12.00228

Suction plate for vacuum block bottom

Dimensions (LxW): 140 x 115 mm

Height H: 16.5 mm

for: Vacuum block VCBL-K1