

Adapter-Plate ISAP-K1 300x200x8


Part no.:10.01.14.00025

<https://www.schmalz.com/10.01.14.00025>



Homepage > Vacuum Clamping Technology > Clamping Equipment for Woodworking > Clamping Equipment for 1-Circuit Systems > Adapter-Plates ISAP-K1 > ISAP-K1 300x200x8

Adapter-Plate Innospann for Schmalz 1-circuit console

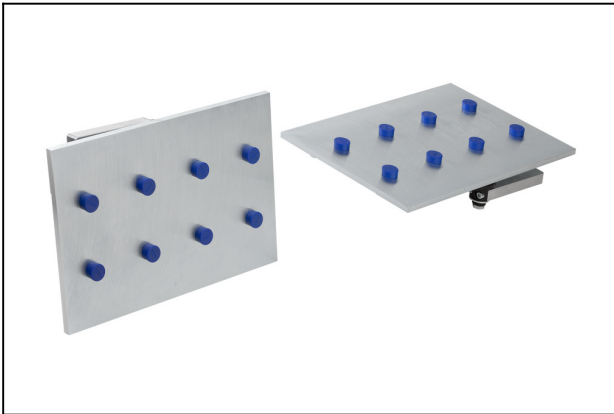


Length L: 300 mm

Width B: 200 mm

Height H: 8 mm

Design Data

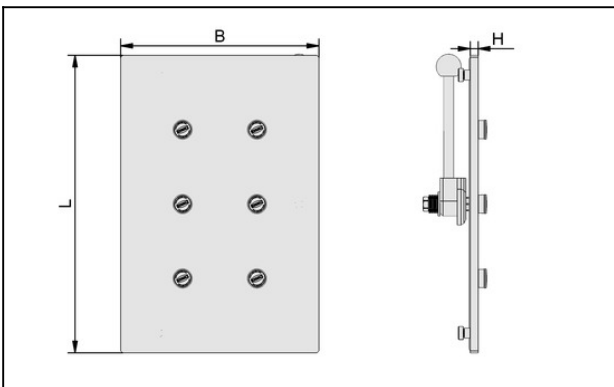

Attribute	Value
-----------	-------

B	200 mm
---	--------

H	8 mm
---	------

L	300 mm
---	--------

Technical Data

Attribute	Value
-----------	-------

Weight	2.05 kg
--------	---------

Adapter-Plate ISAP-K1 300x200x8

Part no.:10.01.14.00025

<https://www.schmalz.com/10.01.14.00025>



Spare Parts



ISMST 19-7 4ISMST

Part no.10.01.14.00847

Sealing magnet for clamping system Innospann

Head diameter Dk: 19 mm

External diameter D: 7 mm

contains: 4 Magnetic sealing plug

Accessories



ISCUP Cup 1 80x80x16

Part no.10.01.15.00209

Suction cup for Innospann

Dimensions (LxW): 80 x 80 mm

Height H: 16 mm



ISCUP Cup 2 80x40x16

Part no.10.01.15.00210

Suction cup for Innospann

Dimensions (LxW): 80 x 40 mm

Height H: 16 mm

Adapter-Plate ISAP-K1 300x200x8

Part no.:10.01.14.00025

<https://www.schmalz.com/10.01.14.00025>



ISCUP Cup 3 80x28x16

Part no.10.01.15.00211

Suction cup for Innospann

Dimensions (LxW): 80 x 28 mm

Height H: 16 mm



ISMB 80x80x26

Part no.10.01.15.00214

Mono-Base for Steelplate and Adapterplate

Basic area: 80 x 80 mm mm

Height H: 26 mm