

Adapter-Plate ISAP-K2 200x200x28


Part no.:10.01.14.00029

<https://www.schmalz.com/10.01.14.00029>

Homepage > Vacuum Clamping Technology > Clamping Equipment for Woodworking > Clamping Equipment for 2-Circuit Systems > Adapter-Plates ISAP-K2 > ISAP-K2 200x200x28



Adapter-Plate Innospann for Schmalz 2-circuit console

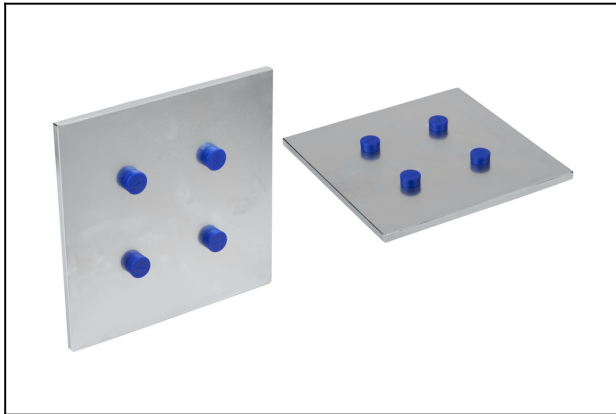


Length L: 200 mm

Width B: 200 mm

Height H: 28 mm

Design Data

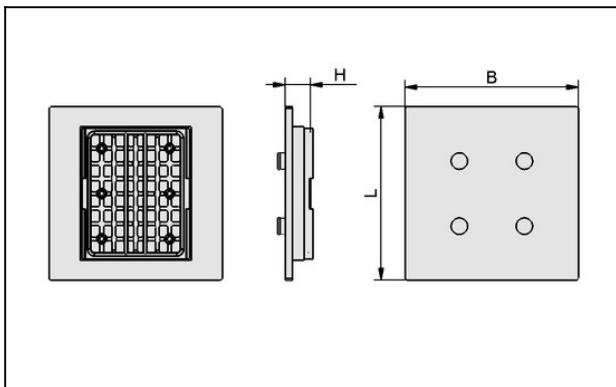

Attribute	Value
-----------	-------

B	200 mm
---	--------

H	28 mm
---	-------

L	200 mm
---	--------

Technical Data

Attribute	Value
-----------	-------

Weight	2.95 kg
--------	---------

Adapter-Plate ISAP-K2 200x200x28

Part no.:10.01.14.00029

<https://www.schmalz.com/10.01.14.00029>



Spare Parts



ISMST 19-7 4ISMST

Part no.10.01.14.00847

Sealing magnet for clamping system Innospann

Head diameter Dk: 19 mm

External diameter D: 7 mm

contains: 4 Magnetic sealing plug

Accessories



ISCUP Cup 1 80x80x30

Part no.10.01.15.00003

Suction cup for Innospann

Dimensions (LxW): 80 x 80 mm

Height H: 30 mm



ISCUP Cup 2 80x40x30

Part no.10.01.15.00004

Suction cup for Innospann

Dimensions (LxW): 80 x 40 mm

Height H: 30 mm

Adapter-Plate

ISAP-K2 200x200x28

Part no.:10.01.14.00029

<https://www.schmalz.com/10.01.14.00029>



ISUP Cup 3 80x28x30

Part no.10.01.15.00005

Suction cup for Innospann

Dimensions (LxW): 80 x 28 mm

Height H: 30 mm



ISMB 80x80x42

Part no.10.01.15.00078

Mono-Base for Steelplate and Adapterplate

Basic area: 80 x 80 mm

Height H: 42 mm