

## Cup

### ISCUP Cup 1 80x80x16

Part no.:10.01.15.00209

<https://www.schmalz.com/10.01.15.00209>



Homepage > Vacuum Clamping Technology > Clamping Equipment for Woodworking > Flexibilization of CNC Machining Centers > Innospann  
clamping equipment ISCUP/ISMB/ISQB > ISCUP Cup 1 80x80x16


## Suction cup for Innospann



Dimensions (LxW): 80 x 80 mm

Height H: 16 mm

## Design Data

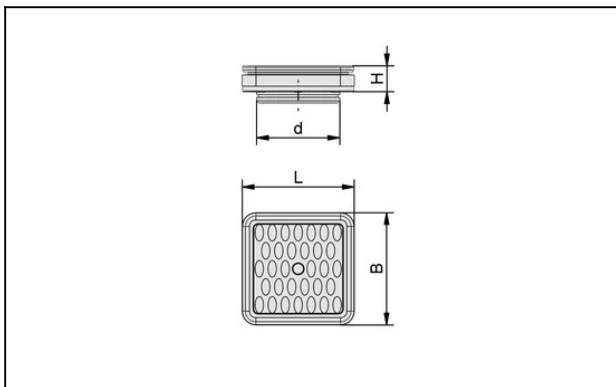

| Attribute | Value |
|-----------|-------|
| B         | 80 mm |
| d         | 60 mm |
| H         | 16 mm |
| L         | 80 mm |

## Technical Data

| Attribute | Value    |
|-----------|----------|
| Weight    | 0.065 kg |

## Cup


### ISCUP Cup 1 80x80x16

Part no.:10.01.15.00209

<https://www.schmalz.com/10.01.15.00209>



#### Spare Parts

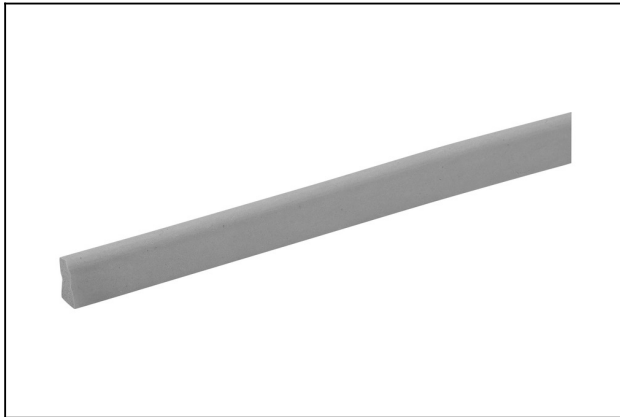

##### **DI-PROF 4x10 MOS EPDM HR**

Part no.10.01.15.00062

Sealing section for construction of specific gripper solutions


Width B: 4 mm

Height H: 10 mm

Material-Type: Foam rubber

Sealing material: EPDM

Shape: half-round

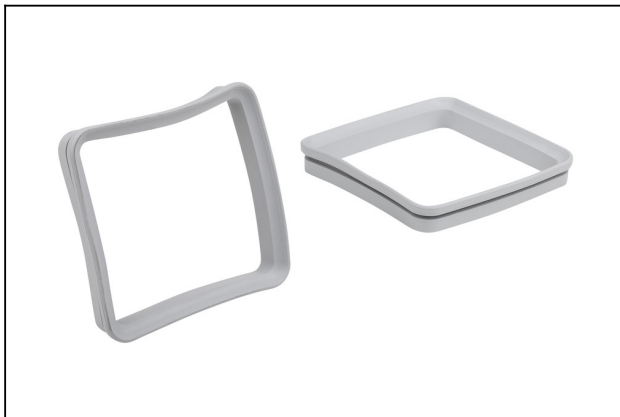

##### **ISDR 81x81x12 Cup 1 NK-50**

Part no.10.01.15.00020

Sealing frame

Length L: 81 mm


Width B: 81 mm

Height H: 12 mm

Type: Cup 1

Suction cup material:

Natural Rubber NK 50±5

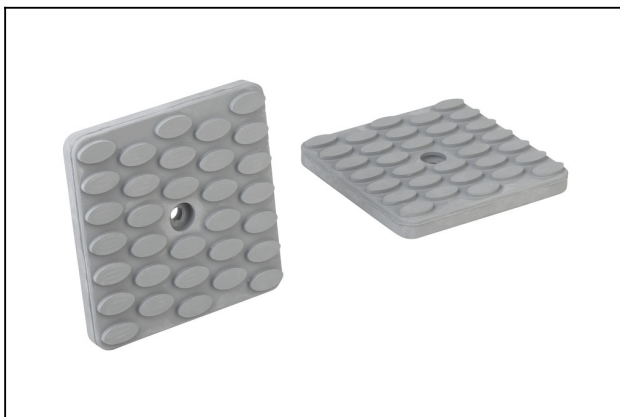

##### **ISRPL 66x66x8.5**

Part no.10.01.15.00017

Friction plate

Length L: 66 mm

Width B: 66 mm

Height H: 8.5 mm

Type: Cup 1