

Steel-Plate

ISST-MPL 400x300x3


Part no.:10.01.14.01125

<https://www.schmalz.com/10.01.14.01125>



Homepage > Vacuum Clamping Technology > Clamping Equipment for Metal and Plastic Processing > Innospann Systems for Metal and Plastic Processing > Innospann Steel-Plate System ISST-MPL > ISST-MPL 400x300x3

Steelplate for use with Matrix-Plate

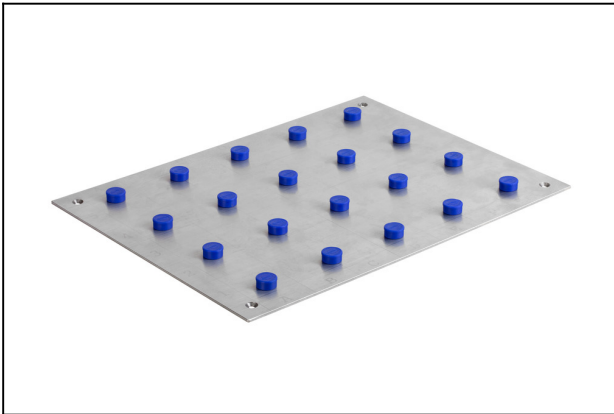


Length L: 400 mm

Width B: 300 mm

Height H: 3 mm

Spare Parts

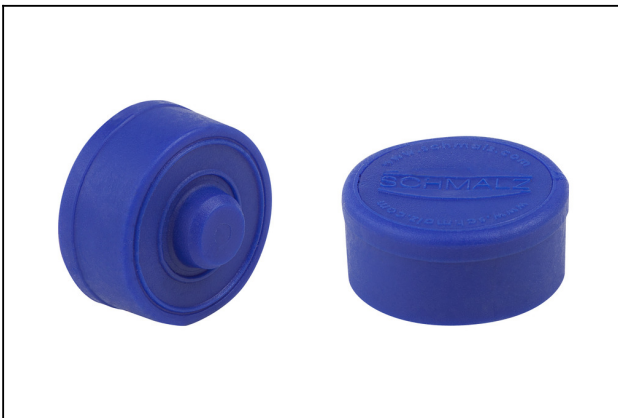

ISMST 19-7 4ISMST

Part no.10.01.14.00847

Sealing magnet for clamping system Innospann

Head diameter Dk: 19 mm

External diameter D: 7 mm


contains: 4 Magnetic sealing plug

Steel-Plate

ISST-MPL 400x300x3

Part no.:10.01.14.01125

<https://www.schmalz.com/10.01.14.01125>

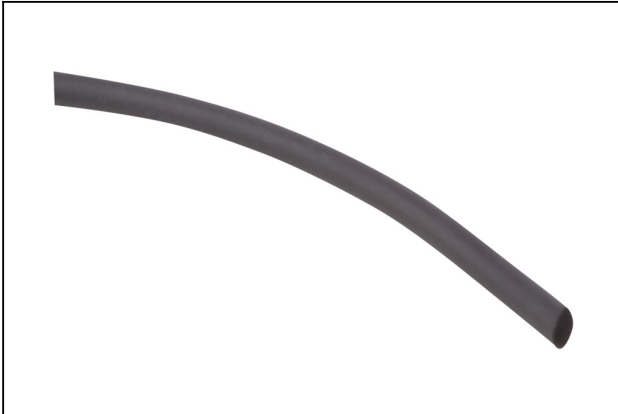

DI-SCHN 3.5 MOS CR-20

Part no.10.07.04.00091

Sealing cord

External diameter D: 3.5 mm

Material-Type: Foam rubber

Sealing material: Chloroprene CR

Material hardness: 20 °Sh