

Cup

ISCUP Cup 2 80x40x30

Part no.:10.01.15.00004

<https://www.schmalz.com/10.01.15.00004>



Homepage > Vacuum Clamping Technology > Clamping Equipment for Woodworking > Flexibilization of CNC Machining Centers > Innospann
clamping equipment ISCUP/ISMB/ISQB > ISCUP Cup 2 80x40x30


Suction cup for Innospann



Dimensions (LxW): 80 x 40 mm

Height H: 30 mm

Design Data

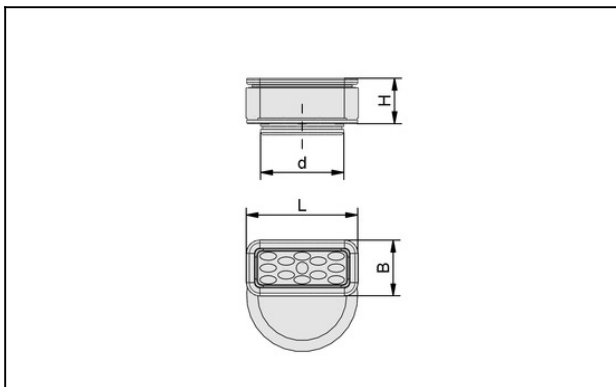

Attribute	Value
B	40 mm
d	60 mm
H	30 mm
L	80 mm

Technical Data

Attribute	Value
Weight	0.092 kg

Cup


ISCUP Cup 2 80x40x30

Part no.:10.01.15.00004

<https://www.schmalz.com/10.01.15.00004>



Spare Parts

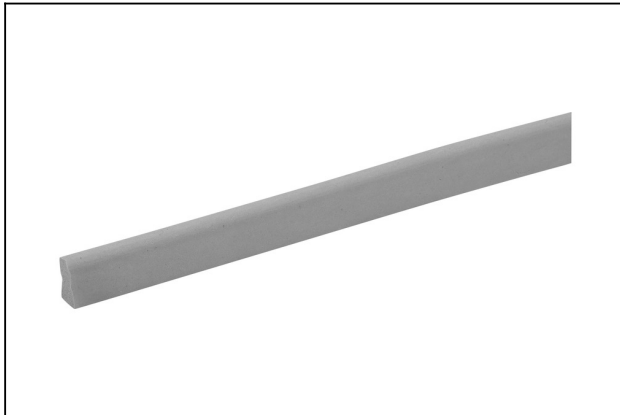

DI-PROF 4x10 MOS EPDM HR

Part no.10.01.15.00062

Sealing section for construction of specific gripper solutions


Width B: 4 mm

Height H: 10 mm

Material-Type: Foam rubber

Sealing material: EPDM

Shape: half-round

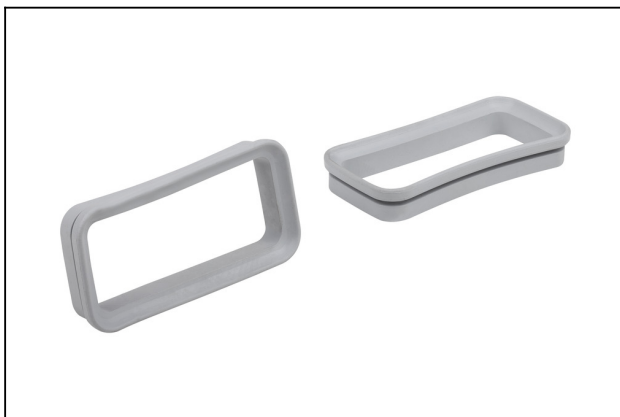

ISDR 81x43x12 Cup 2 NK-50

Part no.10.01.15.00021

Sealing frame

Length L: 81 mm


Width B: 43 mm

Height H: 12 mm

Type: Cup 2

Suction cup material:

Natural Rubber NK 50±5

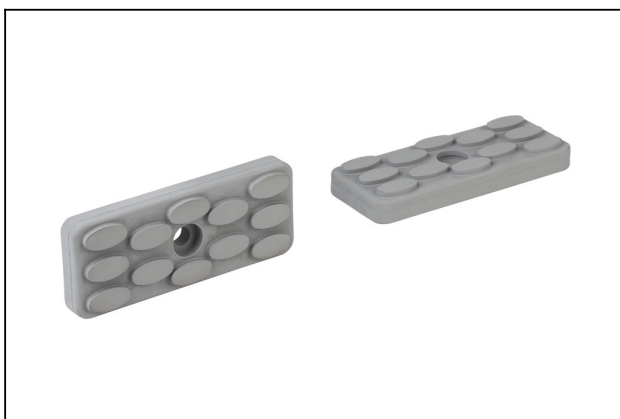

ISRPL 66x26x8.5

Part no.10.01.15.00018

Friction plate

Length L: 66 mm

Width B: 26 mm

Height H: 8.5 mm

Type: Cup 2