

## Adapter-Plate AP-G-130x130x26

Part no.:10.01.12.03876

<https://www.schmalz.com/10.01.12.03876>



Homepage > Vacuum Clamping Technology > Clamping Equipment for Woodworking > Clamping Equipment for Nesting Table Systems >

Adapter-Plates AP-G > AP-G-130x130x26

### Adapter-Plate AP for usage of Vacuum Blocks VCBL-B



for: Smooth Table Systems


Working height H1 (max): 100 mm

Length L: 130 mm

Width B: 130 mm

Height H: 26 mm

### Design Data

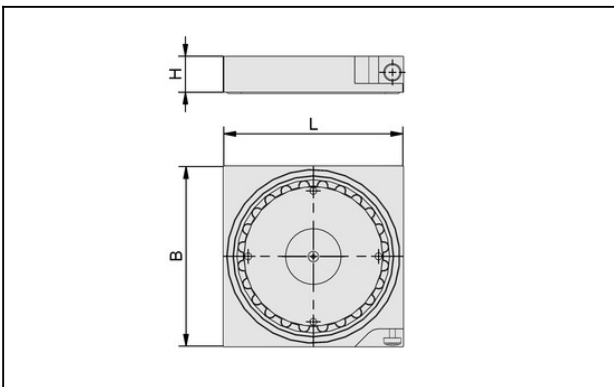

#### Attribute

#### Value

|   |        |
|---|--------|
| B | 130 mm |
| H | 26 mm  |
| L | 130 mm |

### Accessories

## Adapter-Plate AP-G-130x130x26

Part no.:10.01.12.03876

<https://www.schmalz.com/10.01.12.03876>



### **VCBL-B 140x130x29 TV**

Part no.10.01.12.03165

Vacuum block

Dimensions (LxW): 140 x 130 mm

Height H: 29 mm

with: Sensing valve



### **VCBL-B 140x130x48 TV**

Part no.10.01.12.03169

Vacuum block

Dimensions (LxW): 140 x 130 mm

Height H: 48 mm

with: Sensing valve



### **VCBL-B 140x130x74 TV**

Part no.10.01.12.03173

Vacuum block

Dimensions (LxW): 140 x 130 mm

Height H: 74 mm

with: Sensing valve

## Adapter-Plate AP-G-130x130x26

Part no.:10.01.12.03876

<https://www.schmalz.com/10.01.12.03876>



### **VCBL-B 125x75x29 TV**

Part no.10.01.12.03166

Vacuum block

Dimensions (LxW): 125 x 75 mm

Height H: 29 mm

with: Sensing valve



### **VCBL-B 125x75x48 TV**

Part no.10.01.12.03170

Vacuum block

Dimensions (LxW): 125 x 75 mm

Height H: 48 mm

with: Sensing valve



### **VCBL-B 125x75x74 TV**

Part no.10.01.12.03174

Vacuum block

Dimensions (LxW): 125 x 75 mm

Height H: 74 mm

with: Sensing valve

## Adapter-Plate AP-G-130x130x26

Part no.:10.01.12.03876

<https://www.schmalz.com/10.01.12.03876>



### **VCBL-B 120x50x29 TV**

Part no.10.01.12.03167

Vacuum block

Dimensions (LxW): 120 x 50 mm

Height H: 29 mm

with: Sensing valve



### **VCBL-B 120x50x48 TV**

Part no.10.01.12.03171

Vacuum block

Dimensions (LxW): 120 x 50 mm

Height H: 48 mm

with: Sensing valve



### **VCBL-B 120x50x74 TV**

Part no.10.01.12.03175

Vacuum block

Dimensions (LxW): 120 x 50 mm

Height H: 74 mm

with: Sensing valve

## Adapter-Plate AP-G-130x130x26

Part no.:10.01.12.03876

<https://www.schmalz.com/10.01.12.03876>



### **VCBL-B 130x30x29 TV**

Part no.10.01.12.03168

Vacuum block

Dimensions (LxW): 130 x 30 mm

Height H: 29 mm

with: Sensing valve



### **VCBL-B 130x30x48 TV**

Part no.10.01.12.03172

Vacuum block

Dimensions (LxW): 130 x 30 mm

Height H: 48 mm

with: Sensing valve



### **VCBL-B 130x30x74 TV**

Part no.10.01.12.03176

Vacuum block

Dimensions (LxW): 130 x 30 mm

Height H: 74 mm

with: Sensing valve

## Adapter-Plate

AP-G-130x130x26

Part no.:10.01.12.03876

<https://www.schmalz.com/10.01.12.03876>



### STV-W G1/4-AG 4

Part no.10.08.02.00157

Push-in Fitting, swivelling elbow

Thread G1: G1/4"-M

External hose diameter: 4 mm

Material: Brass, nickel-plated

Ambient temperature: -20 ... 80 °C



### STV-W G1/4-AG 6

Part no.10.08.02.00159

Push-in Fitting, swivelling elbow

Thread G1: G1/4"-M

External hose diameter: 6 mm

Material: Brass, nickel-plated

Ambient temperature: -20 ... 80 °C



### STV-W G1/4-AG 8

Part no.10.08.02.00161

Push-in Fitting, swivelling elbow

Thread G1: G1/4"-M

External hose diameter: 8 mm

Material: Brass, nickel-plated

Ambient temperature: -20 ... 80 °C

## Adapter-Plate

### AP-G-130x130x26

Part no.:10.01.12.03876

<https://www.schmalz.com/10.01.12.03876>



#### **STV-W G1/4-AG 10**

Part no.10.08.02.00254

Push-in Fitting, swivelling elbow

Thread G1: G1/4"-M

External hose diameter: 10 mm

Material: Brass, nickel-plated

Ambient temperature: -20 ... 80 °C



#### **STV-W G1/4-AG 12**

Part no.10.08.02.00162


Push-in Fitting, swivelling elbow

Thread G1: G1/4"-M

External hose diameter: 12 mm

Material: Brass, nickel-plated

Ambient temperature: -20 ... 80 °C

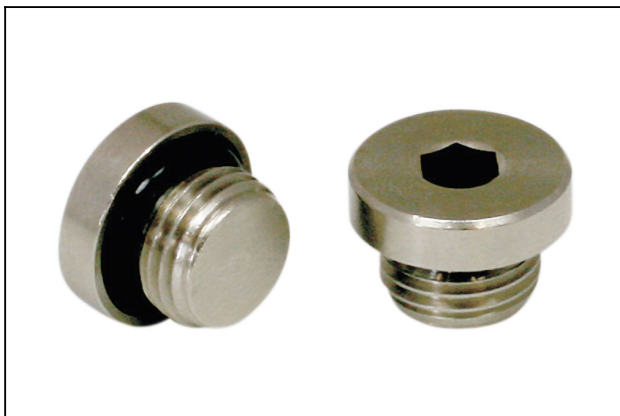

#### **VRS-SB G1/4-AG ISKT O-Ring**

Part no.10.08.06.00044

Sealing screw with collar

Thread G1: G1/4"-M

Material: Brass

Surface: nickel plated