

Vacuum block Innospann

ISBL 80x28x38

Part no.:10.01.15.00656

<https://www.schmalz.com/10.01.15.00656>



Homepage > Vacuum Clamping Technology > Clamping Equipment for Metal and Plastic Processing > Innospann Systems for Metal and Plastic Processing > Innospann Steel-Plate System ISST-MPL > ISBL 80x28x38

Innospann vacuum block for Steelplate and Adapterplate



Dimensions (LxW): 80 x 28 mm

Basic area: 80 x 80 mm mm

Height H: 38 mm

Spare Parts



ISDR 81x31x12 Cup 3 NBR-50

Part no.10.01.15.00419

Sealing frame

Length L: 81 mm

Width B: 31 mm

Height H: 12 mm

Type: Cup 3

Suction cup material:


Perbunan NBR 50±5ShA

Vacuum block Innospann

ISBL 80x28x38

Part no.:10.01.15.00656

<https://www.schmalz.com/10.01.15.00656>

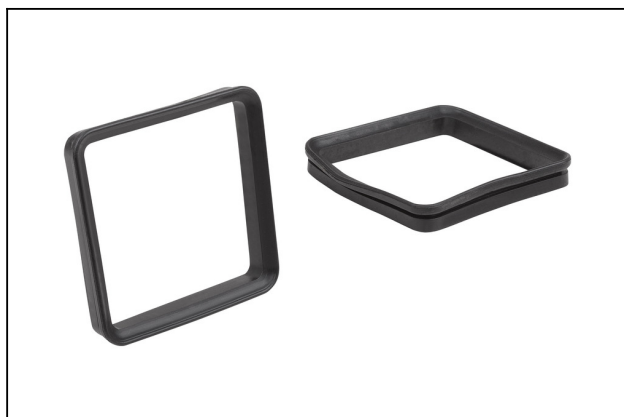

ISDR 81x81x12 Cup 1 NBR-50

Part no.10.01.15.00158

Sealing frame

Length L: 81 mm

Width B: 81 mm

Height H: 12 mm

Type: Cup 1

Suction cup material:

Perbunan NBR 50±5ShA