

Vacuum block

VCBL-GL D120x93.5


Part no.:10.01.18.00587

<https://www.schmalz.com/10.01.18.00587>



Homepage > Vacuum Clamping Technology > Clamping Equipment for Glass Processing > Flat Table Systems for Glass Processing > Vacuum block VCBL-GL > VCBL-GL D120x93.5

Vacuum block for smooth table with 2 hose connections

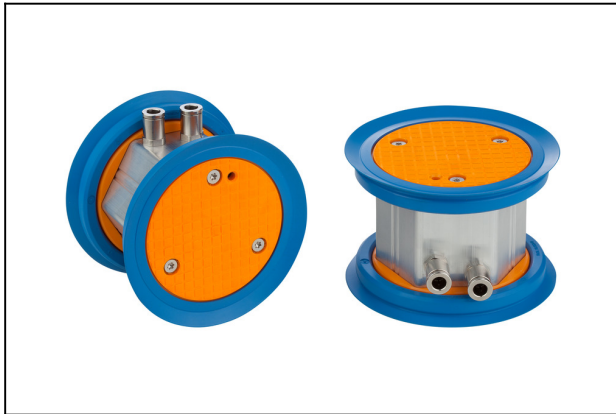

Dimensions (LxW): Diameter 120 mm mm

Height H: 93.5 mm


Internal hose diameter (recom.): 6 mm

Sealing material:

High temp material HT1

Material workpiece support: Elastodur

Design Data

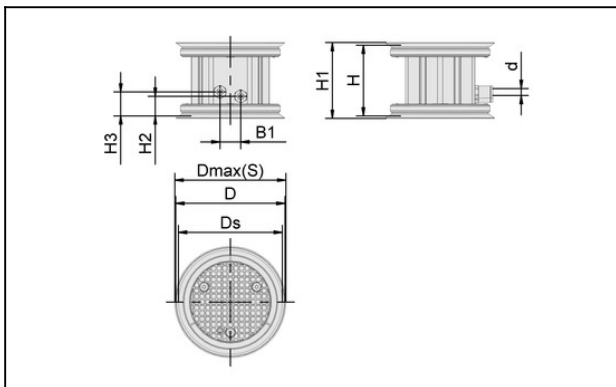

Attribute	Value
-----------	-------

B1	24 mm
----	-------

d	8 mm
---	------

D	126 mm
---	--------

Dmax(S)	128 mm
---------	--------

Ds	120 mm
----	--------

H	93.5 mm
---	---------

H1	99.5 mm
----	---------

H2	22.5 mm
----	---------

H3	27.5 mm
----	---------

Technical Data

[Contact to Schmalz](#)

Schmalz Sp.z.o.o. | Kobaltowa 4, 62-002 Złotniki, Polen | +48 22 460 49 70 | schmalz@schmalz.pl

Page 1 of 3

Vacuum block

VCBL-GL D120x93.5


Part no.:10.01.18.00587

<https://www.schmalz.com/10.01.18.00587>



Attribute	Value
Weight	0.8 kg

Spare Parts

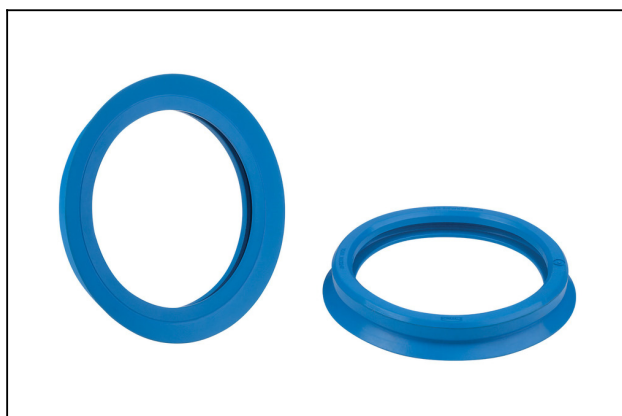

DR 120/88.5x16.5 HT1-60

Part no.10.01.18.00249

Sealing ring for suction plate

External diameter D: 120 mm

Internal diameter d: 88.5 mm

Length L: 16.5 mm

Material hardness: 60 °Sh

Accessories



VSL 8-6 PU

Part no.10.07.09.00003

Hose for vacuum and compressed-air systems

External diameter D: 8 mm

Internal diameter d: 6 mm

Length (max): 500 m

Material: PU

Installation radius (min): 45 mm

Pressure range (operating pressure):

-0.95 ... 10.00 bar

 
Ambient temperature: -20 ... 90 °C

Vacuum block

VCBL-GL D120x93.5

Part no.:10.01.18.00587


<https://www.schmalz.com/10.01.18.00587>



ZUB VCBL-GL

Part no.10.01.18.00493

 Accessories-clamping systems
for: Vacuum block VCBL-GL
and: Screw plug connection



ZUB VCBL-GL

Part no.10.01.18.00492

Accessories-clamping systems
for: Vacuum block VCBL-GL
and: Multi-way manual