

Universal holder

HTR-UNI 2N G2 200


Part no.:10.01.03.00309

<https://www.schmalz.com/10.01.03.00309>



Homepage > Vacuum Technology for Automation > Vacuum Components > Mounting Elements > Holder for Suction Cups and Spring Plungers
> Universal Holders HTR-UNI > HTR-UNI 2N G2 200

Universal holder for adjustable mounting of suction cups

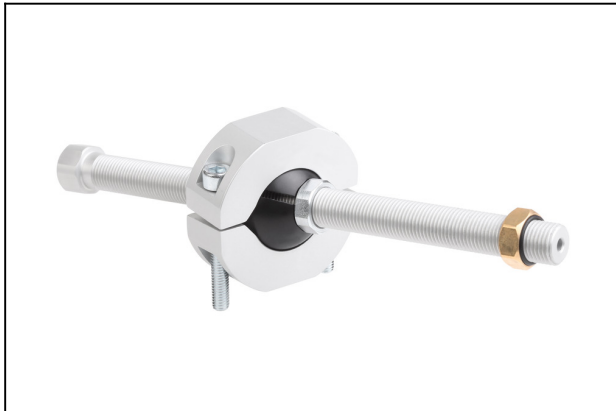

Cross-beam connection:


2 Sliding blocks

Suction cup connection: G1/4"-M

Overall length: 200 mm

Ambient temperature: 0 ... 80 °C

Design Data

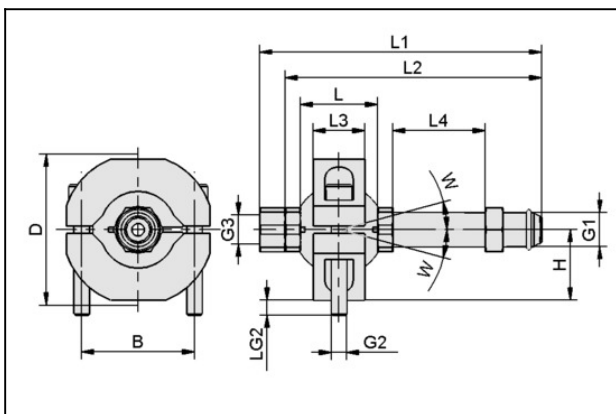

Attribute	Value
-----------	-------

B	44 mm
---	-------

D	59 mm
---	-------

G1	G1/4"-AG
----	----------

G2	M6-M
----	------

G3	G1/4"-F
----	---------

H	27.5 mm
---	---------

L	30 mm
---	-------

L1	200 mm
----	--------

L2	190 mm
----	--------

L3	20 mm
----	-------

L4	126 mm
----	--------

LG2	6 mm
-----	------

W	15 °
---	------

Universal holder

HTR-UNI 2N G2 200

Part no.:10.01.03.00309


<https://www.schmalz.com/10.01.03.00309>



Technical Data

Attribute	Value
Weight	222.1 g

Spare Parts

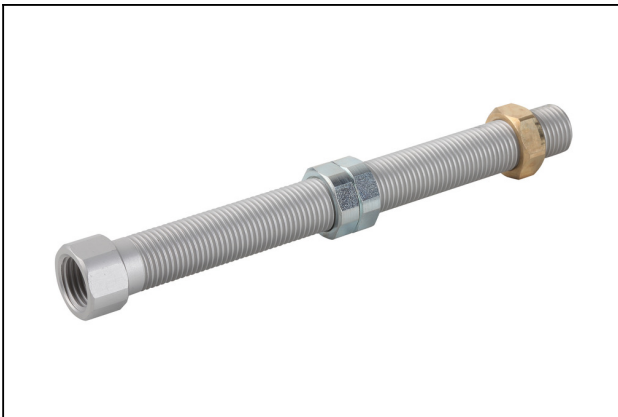

SAUG-ANB G1/4-AG 200

Part no.10.01.03.00308

Suction cup connection (rigid)

Suction cup connection: G1/4"-M

Length L: 200 mm

Accessories



STV-GE G1/4-AG 10

Part no.10.08.02.00251

Push-in Fitting, straight

Thread G1: G1/4"-M

External hose diameter: 10 mm

Material: Brass

Surface: nickel plated

Ambient temperature: -20 ... 80 °C

Universal holder

HTR-UNI 2N G2 200

Part no.:10.01.03.00309

<https://www.schmalz.com/10.01.03.00309>



STV-GE G1/4-AG 12

Part no.10.08.02.00208

Push-in Fitting, straight

Thread G1: G1/4"-M

External hose diameter: 12 mm

Material: Brass

Surface: nickel plated

Ambient temperature: -20 ... 80 °C



STV-GE G1/4-AG 8

Part no.10.08.02.00207

Push-in Fitting, straight

Thread G1: G1/4"-M

External hose diameter: 8 mm

Material: Brass

Surface: nickel plated

Ambient temperature: -20 ... 80 °C



STV-GE G1/4-AG 6

Part no.10.08.02.00205

Push-in Fitting, straight

Thread G1: G1/4"-M

External hose diameter: 6 mm

Material: Brass

Surface: nickel plated


Ambient temperature: -20 ... 80 °C

Universal holder

HTR-UNI 2N G2 200

Part no.:10.01.03.00309

<https://www.schmalz.com/10.01.03.00309>

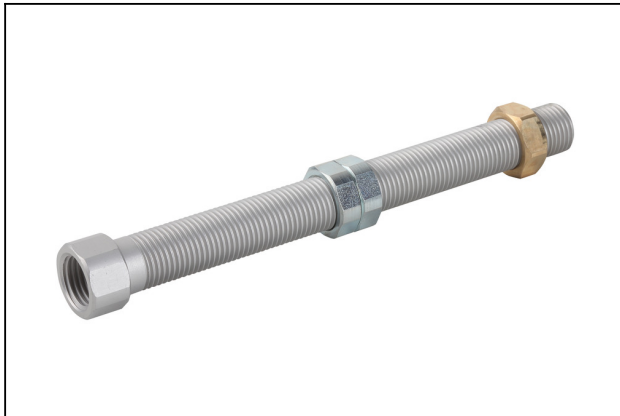

SAUG-ANB G1/4-AG 80

Part no.10.01.03.00292

Suction cup connection (rigid)

Suction cup connection: G1/4"-M

Length L: 80 mm