

Vacuum pump EVE-TR 8 DC


Part no.:10.03.01.00288

<https://www.schmalz.com/10.03.01.00288>



Homepage > Vacuum Technology for Automation > Vacuum Components > Vacuum Generators > Vacuum Pumps > Dry-Running Vacuum Pumps EVE-TR > EVE-TR 8 DC

Oil-free pump with constant suction rate, robust, requires little maintenance

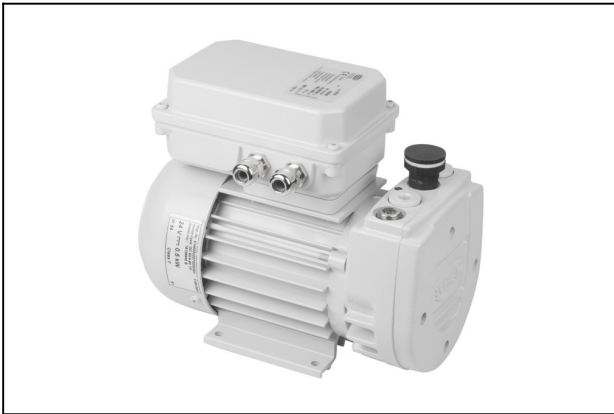

Noise level (50 Hz): 60.5 dB


Voltage: 24V - DC

Suction rate at DC: 9.7 m³/h

Rated power: 500 W

Weight: 12 kg

Design Data

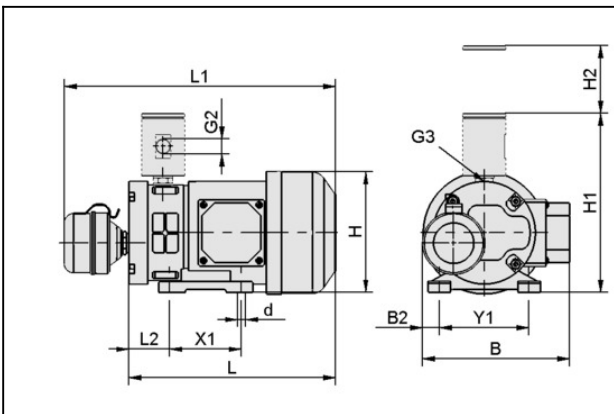

Attribute	Value
-----------	-------

B	136 mm
---	--------

B2	8 mm
----	------

d	8.4 mm
---	--------

G3	G3/8"-F
----	---------

H	196 mm
---	--------

L	231 mm
---	--------

L2	72 mm
----	-------

X1	80 mm
----	-------

Y1	100 mm
----	--------

Technical Data

[Contact to Schmalz](#)

Schmalz Sp.z.o.o. | Kobaltowa 4, 62-002 Złotniki, Polen | +48 22 460 49 70 | schmalz@schmalz.pl

Page 1 of 3

Vacuum pump

EVE-TR 8 DC

Part no.:10.03.01.00288

<https://www.schmalz.com/10.03.01.00288>



Attribute	Value
Suction rate at DC	9.7 m³/h
Voltage	24V - DC
Rated power	500 W
Current type	DC
Sound level at 50 Hz	60.5 dB(A)
Weight	12 kg

Noise level according to DIN EN ISO 3744 (KpA = 3 dB(A)), interval of 1 m, at medium load, both connection sides piped

Spare Parts



FILT-EINS 10 28x51 PAP VF-3/8

Part no.10.07.01.00014

Filter insert (round)

Filter pore size: 10 µm

External diameter D: 28 mm

Length L: 51 mm

Filter material: Paper

for: Filter VF

Size: 3/8

Accessories



VBV -850...0 G3/8-AG EVE 4-8

Part no.10.03.01.00107

Vacuum valve for limiting the maximum vacuum pressure

Vacuum range: -850 ... 0 mbar

Thread G1: G3/8"-M

Length L: 45 mm

for: Pump EVE

Size: 4-8

Vacuum pump

EVE-TR 8 DC

Part no.:10.03.01.00288

<https://www.schmalz.com/10.03.01.00288>

