

Vacuum hose

VSL 42-32 PU-DS-AS

Part no.:10.07.09.00036


<https://www.schmalz.com/10.07.09.00036>



Homepage > Vacuum Technology for Automation > Vacuum Components > Filters and Connections > Hoses and Connectors > Vacuum /


Compressed Air Hoses VSL > VSL 42-32 PU-DS-AS

Hose for vacuum and compressed-air systems

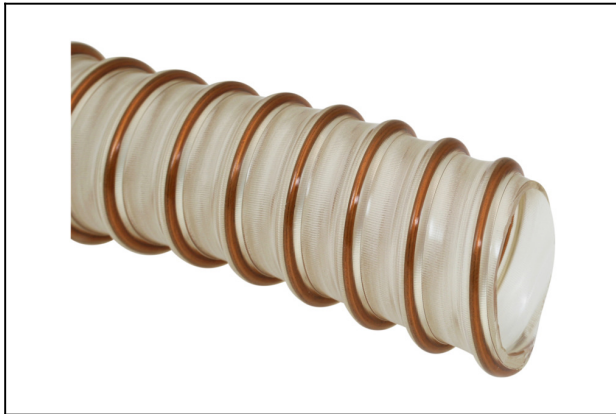

External diameter D: 42 mm
Internal diameter d: 32 mm
Length (max): 20 m
Material: PU, wire spiral, antistat
Installation radius (min): 25 mm
Colour: Transparent
Pressure range (operating pressure):
-1.00 ... 3.77 bar
Ambient temperature: -40 ... 90 °C

Design Data

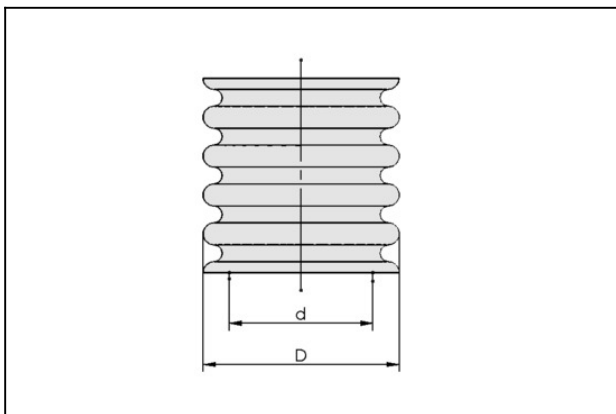

Attribute	Value
d	32 mm
D	42 mm

Technical Data

Attribute	Value
Hose type	42-32
Pressure range (operating pressure)	-0,95 ... 3,20 bar

[Contact to Schmalz](#)

Schmalz Sp.z.o.o. | Kobaltowa 4, 62-002 Złotniki, Polen | +48 22 460 49 70 | schmalz@schmalz.pl

Page 1 of 3

Vacuum hose

VSL 42-32 PU-DS-AS

Part no.:10.07.09.00036

<https://www.schmalz.com/10.07.09.00036>



Attribute	Value
Operating temperature	-20 ... 90 °C
Bending radius min.	25 mm
Length max.	20 m
Weight/Meter	440 g/m
Weight/Meter	0.44 kg/m

Note: Operating pressure: In reference to media and ambient temperature of + 20°C Bending radius: Referred to the inner side of the hose bend in a static state Max. length: Please indicate the tube length when placing the order!

Accessories



SSD 35-40 ST-VZ

Part no.10.07.10.00018

Hose clamp for securing wire-reinforced hoses

Clamping range: 35.0 ... 40.0 mm

Material: Steel

Surface: galvanised



KAPP 9 Band

Part no.20.12.01.00036

Cap (rectangular)

Length L: 9 mm

Size: Band

Vacuum hose

VSL 42-32 PU-DS-AS

Part no.:10.07.09.00036

<https://www.schmalz.com/10.07.09.00036>



SSD 38-43 ST-VZ

Part no.10.07.10.00019

Hose clamp for securing wire-reinforced hoses

Clamping range: 38.0 ... 43.0 mm

Material: Steel

Surface: galvanised



ST G1-AG 32 MS-V

Part no.10.08.03.00168

Hose sleeve

Thread G1: G1"-M

Internal hose diameter: 32 mm

Material: Brass

Surface: nickel plated



ST G1-1/4-AG 32 MS-V

Part no.10.08.03.00169

Hose sleeve

Thread G1: G1-1/4"-M

Internal hose diameter: 32 mm

Material: Brass

Surface: nickel plated