

Plug union, straight STV-GE G3/8-AG 8

Part no.:10.08.02.00237

<https://www.schmalz.com/10.08.02.00237>

Homepage > Vacuum Technology for Automation > Vacuum Components > Filters and Connections > Hoses and Connectors > Screw in Push Fittings > STV-GE G3/8-AG 8




Push-in Fitting, straight



Thread G1: G3/8"-M
External hose diameter: 8 mm
Material: Brass
Surface: nickel plated
Ambient temperature: -20 ... 80 °C

Design Data

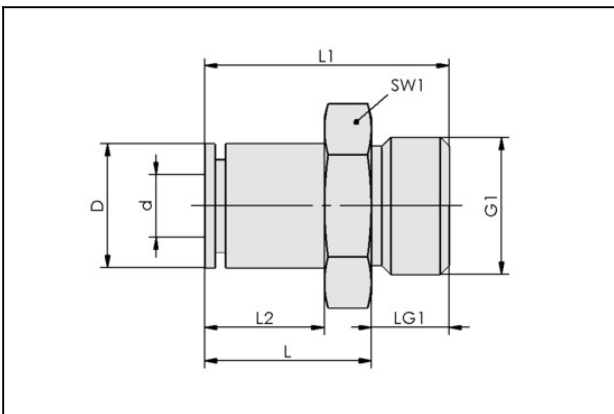

Attribute	Value
-----------	-------

D	14.6 mm
d	8 mm
G1	G3/8"-AG
dn	6 mm
L	17.4 mm
L1	25 mm
L2	11.8 mm
LG1	7.6 mm
SW1	20 mm

Technical Data

[Contact to Schmalz](#)

Schmalz Sp.z.o.o. | Kobaltowa 4, 62-002 Złotniki, Polen | +48 22 460 49 70 | schmalz@schmalz.pl

Page 1 of 2

Plug union, straight STV-GE G3/8-AG 8


Part no.:10.08.02.00237

<https://www.schmalz.com/10.08.02.00237>



Attribute	Value
Hose type	Schlauch D = 8 d = 6
Hose type	8-6
Material	Messing
Pressure range (operating pressure)	-0,95 ... 15,00 bar
Operating temperature	-20 ... 80 °C
Weight	25 g

Accessories

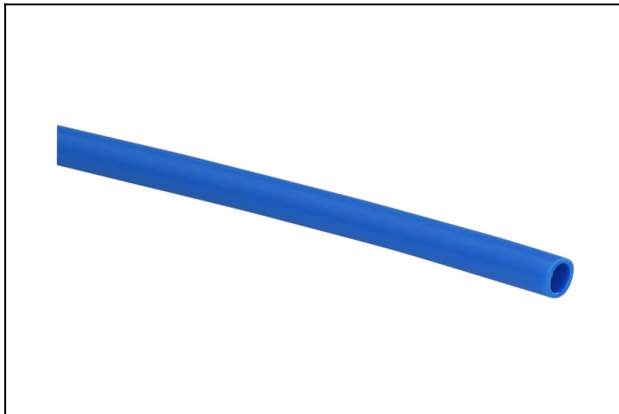

VSL 8-6 PE

Part no.10.07.09.00015

Hose for vacuum and compressed-air systems

External diameter D: 8 mm

Internal diameter d: 6 mm

Length (max): 100 m

Material: PE

Installation radius (min): 45 mm

Pressure range (operating pressure):

-0.95 ... 10.00 bar

Ambient temperature: -30 ... 70 °C



VSL 8-6 PU

Part no.10.07.09.00003

Hose for vacuum and compressed-air systems

External diameter D: 8 mm

Internal diameter d: 6 mm

Length (max): 500 m

Material: PU

Installation radius (min): 45 mm

Pressure range (operating pressure):

-0.95 ... 10.00 bar

Ambient temperature: -20 ... 90 °C