

Vacuum hose

VSL 27-20 PU-DS-AS

Part no.:10.07.09.00047


<https://www.schmalz.com/10.07.09.00047>



Homepage > Vacuum Technology for Automation > Vacuum Components > Filters and Connections > Hoses and Connectors > Vacuum /


Compressed Air Hoses VSL > VSL 27-20 PU-DS-AS

Hose for vacuum and compressed-air systems

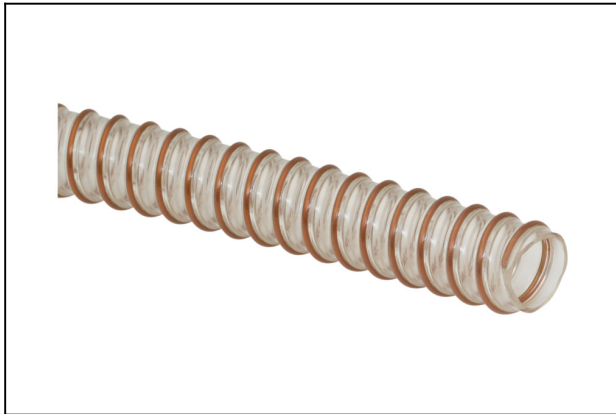

External diameter D: 27 mm
Internal diameter d: 20 mm
Length (max): 20 m
Material: PU, wire spiral, antistat
Installation radius (min): 17 mm
Colour: Transparent
Pressure range (operating pressure):
-1.00 ... 4.72 bar
Ambient temperature: -40 ... 90 °C

Design Data

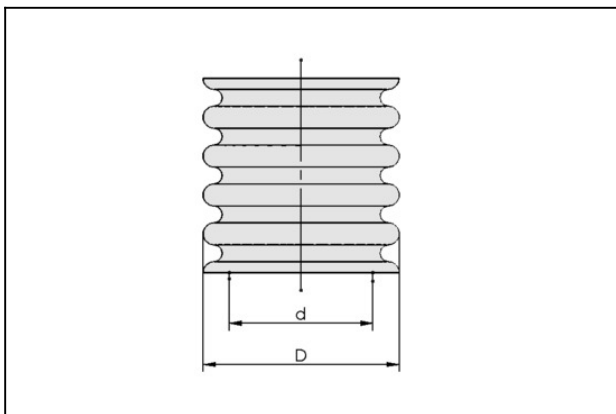

Attribute	Value
d	20 mm
D	27 mm

Technical Data

Attribute	Value
Hose type	27-20
Pressure range (operating pressure)	-0,95 ... 4,00 bar

Vacuum hose

VSL 27-20 PU-DS-AS

Part no.:10.07.09.00047

<https://www.schmalz.com/10.07.09.00047>



Attribute	Value
Operating temperature	-20 ... 90 °C
Bending radius min.	17 mm
Length max.	20 m
Weight/Meter	230 g/m
Weight/Meter	0.23 kg/m

Note: Operating pressure: In reference to media and ambient temperature of + 20°C Bending radius: Referred to the inner side of the hose bend in a static state Max. length: Please indicate the tube length when placing the order!

Accessories



KAPP 9 Band

Part no.20.12.01.00036

Cap (rectangular)

Length L: 9 mm

Size: Band



SSD 24-27 ST-VZ

Part no.10.07.10.00086

Hose clamp for securing wire-reinforced hoses

Clamping range: 24.0 ... 27.0 mm

Material: Steel

Surface: galvanised