

Plug union, straight STV-GE G1/8-AG 8

Part no.:10.08.02.00206

<https://www.schmalz.com/10.08.02.00206>

Homepage > Vacuum Technology for Automation > Vacuum Components > Filters and Connections > Hoses and Connectors > Screw in Push Fittings > STV-GE G1/8-AG 8




Push-in Fitting, straight



Thread G1: G1/8"-M
External hose diameter: 8 mm
Material: Brass
Surface: nickel plated

Design Data

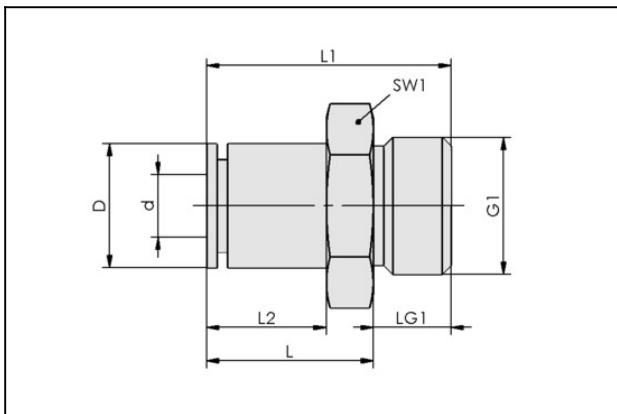

Attribute	Value
-----------	-------

D	14 mm
---	-------

d	8 mm
---	------

G1	G1/8"-AG
----	----------

dn	5.1 mm
----	--------

L	20.7 mm
---	---------

L1	26.2 mm
----	---------

L2	16.4 mm
----	---------

LG1	5.5 mm
-----	--------

SW1	14 mm
-----	-------

Technical Data

[Contact to Schmalz](#)

Schmalz Sp.z.o.o. | Kobaltowa 4, 62-002 Złotniki, Polen | +48 22 460 49 70 | schmalz@schmalz.pl

Page 1 of 2

Plug union, straight

STV-GE G1/8-AG 8


Part no.:10.08.02.00206

<https://www.schmalz.com/10.08.02.00206>



Attribute	Value
Hose type	Schlauch D = 8 d = 6
Hose type	8-6
Material	Messing
Pressure range (operating pressure)	bar
Operating temperature	°C
Weight	16.3 g

Accessories

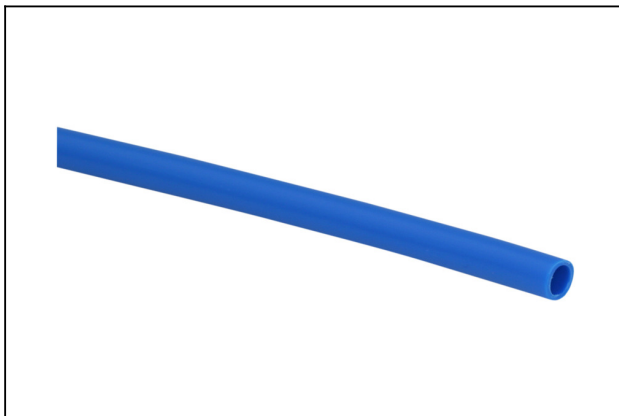

VSL 8-6 PE

Part no.10.07.09.00015

Hose for vacuum and compressed-air systems

External diameter D: 8 mm

Internal diameter d: 6 mm

Length (max): 100 m

Material: PE

Installation radius (min): 45 mm

Pressure range (operating pressure):

-0.95 ... 10.00 bar

Ambient temperature: -30 ... 70 °C



VSL 8-6 PU

Part no.10.07.09.00003

Hose for vacuum and compressed-air systems

External diameter D: 8 mm

Internal diameter d: 6 mm

Length (max): 500 m

Material: PU

Installation radius (min): 45 mm

Pressure range (operating pressure):

-0.95 ... 10.00 bar

Ambient temperature: -20 ... 90 °C