


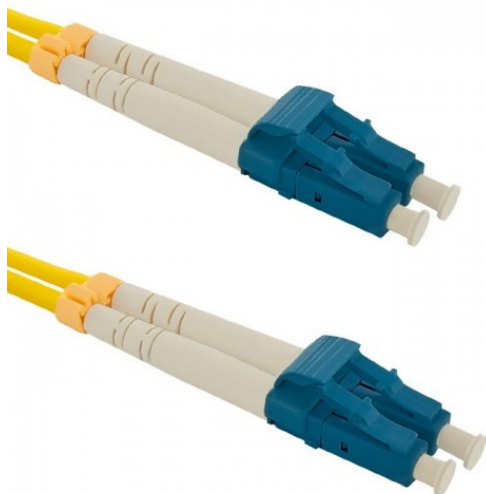

Patchcord fiber optic LC/UPC - LC/UPC | Singlemode | 9/125 | G652D | Duplex | 2m

Product code: 54015

Patchcord fiber optic singlemode

Connectors: LC/UPC - LC/UPC

Standard: G652D

Diameter cable: 3.0 mm

Cable length: 2 m

Technical data

Type connectors	LC/UPC - LC/UPC
Type patchcord	Singlemode
Type of fiber optic transmission	Duplex
Standard fiber	G652D
Fiber type	9/125
Diameter of the mode field	9 m
Diameter fibers sheath	125 m
Sheath	LSZH
Diameter cable	3.0 mm
Insertion loss	<0.3 dB
Return loss	>55 dB
Cable length	2 m
Reinforcing element	Aramid fiber
Colour	Yellow
Additional information	Easy installation and handling on high speed fiber optical transmission networks. LSZH - Outside fireproof cable sheath, which the fire does not emit harmful gases. The product individually tested.
Package	Polybag
Gross weight	0,04 kg
EAN code	5901878540153