
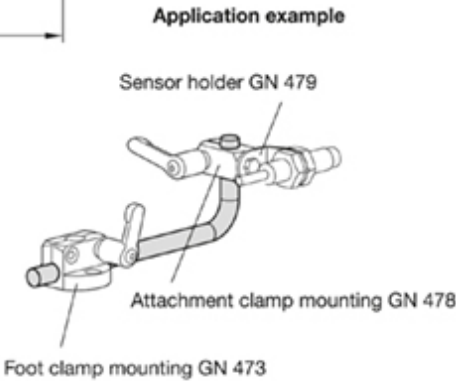


GN 480.3

Stainless Steel-Retaining rods

for clamp mountings, angled

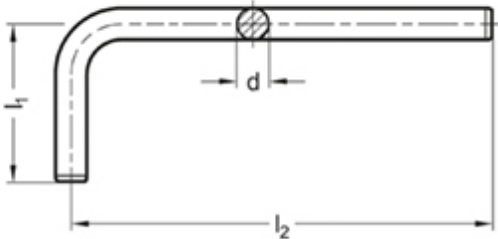

		d	l1	l2		
Description						
GN 480.3-D8-30-90-NI			D 8	30	90	45
GN 480.3-D8-50-150-NI			D 8	50	150	76
GN 480.3-D8-80-240-NI			D 8	80	240	125
GN 480.3-D10-50-150-NI			D 10	50	150	118
GN 480.3-D10-70-210-NI			D 10	70	210	170
GN 480.3-D10-100-300-NI			D 10	100	300	240

Specification

Stainless Steel NI
AISI 304
blank

Information

The dimensions of GN 480.3 Stainless Steel-Retaining rods are tailored for use with clamp mountings. The angled Stainless Steel-Retaining rods make it possible to create compact and space-saving clamp mounting structures efficiently and cost-effectively with few components.

On request

- other dimensions for l1 and l2

Technical information

- [Stainless Steel characteristics](#)