


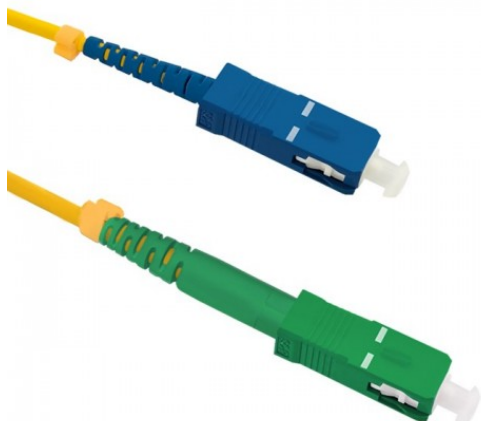

Patchcord fiber optic SC/APC - SC/UPC | Singlemode | 9/125 | G652D | Simplex | 0.5m

Product code: 54288

Patchcord fiber optic singlemode
Connectors: SC/APC -SC/UPC
Standard: G652D
Diameter cable: 3.0 mm
Cable length: 0.5 m

Technical data

Type connectors	SC/APC - SC/UPC
Type patchcord	Singlemode
Type of fiber optic transmission	Simplex
Standard fiber	G652D
Fiber type	9/125
Diameter of the mode field	9 m
Diameter fibers sheath	125 m
Sheath	LSZH
Diameter cable	3.0 mm
Insertion loss	<0.3 dB
Return loss	>60 dB
Cable length	0.5 m
Reinforcing element	Aramid fiber
Colour	Yellow
Additional information	Easy installation and handling on high speed fiber optical transmission networks. LSZH - Outside fireproof cable sheath, which the fire does not emit harmful gases. The product individually tested.
Package	Polybag
Gross weight	0,015 kg
EAN code	5901878542881