


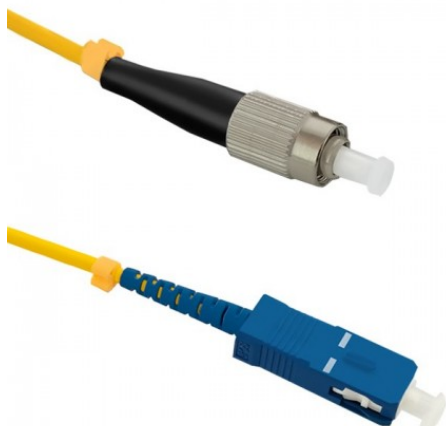

Patchcord fiber optic FC/UPC – SC/UPC | Singlemode | 9/125 | G652D | Simplex | 0.5m

Product code: 54314

Patchcord fiber optic singlemode
Connectors: FC/UPC – SC/UPC
Standard: G652D
Diameter cable: 3.0 mm
Cable length: 0.5 m

Technical data

Type connectors	FC/UPC – SC/UPC
Type patchcord	Singlemode
Type of fiber optic transmission	Simplex
Standard fiber	G652D
Fiber type	9/125
Diameter of the mode field	9 m
Diameter fibers sheath	125 m
Sheath	LSZH
Diameter cable	3.0 mm
Cable length	0.5 m
Reinforcing element	Aramid fiber
Additional information	Easy installation and handling on high speed fiber optical transmission networks. LSZH – Outside fireproof cable sheath, which the fire does not emit harmful gases. The product individually tested.
Package	Polybag
Gross weight	0,017 kg
EAN code	5901878543147