


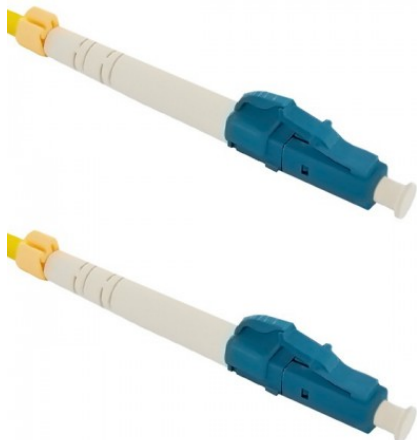

Patchcord fiber optic LC/UPC - LC/UPC | Singlemode | 9/125 | G652D | Simplex | 20m

Product code: 54330

Patchcord fiber optic singlemode
Connectors: LC/UPC - LC/UPC
Standard: G652D
Diameter cable: 3.0 mm
Cable length: 20 m

Technical data

Type connectors	LC/UPC - LC/UPC
Type patchcord	Singlemode
Type of fiber optic transmission	Simplex
Standard fiber	G652D
Fiber type	9/125
Diameter of the mode field	9 m
Diameter fibers sheath	125 m
Sheath	LSZH
Diameter cable	3.0 mm
Cable length	20 m
Reinforcing element	Aramid fiber
Additional information	Easy installation and handling on high speed fiber optical transmission networks. LSZH - Outside fireproof cable sheath, which the fire does not emit harmful gases. The product individually tested.
Package	Polybag
Gross weight	0,133 kg
EAN code	5901878543307