



Order Code	TCK-148
Inductance	82 μ H $\pm$ 20% (at 1 kHz / 1 V)
Impedance (DCR)	2800 mOhm max.
Rated Current	0.25 A max.
Operating Temperature	-40°C to +125°C



Impedance Curve

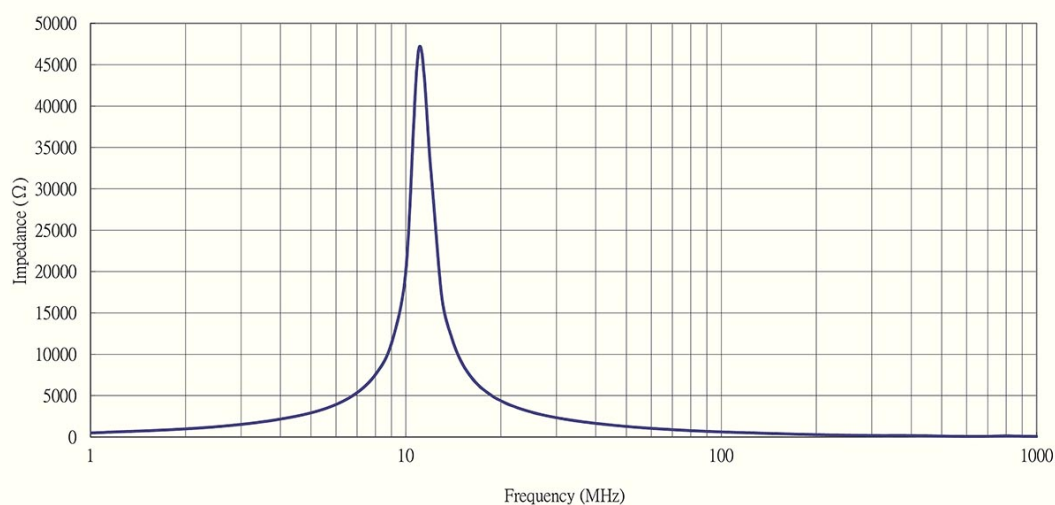


Outline Dimensions

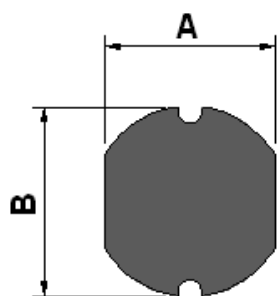

Dimensions [mm]

A	3.1 $\pm$ 0.5
B	3.5 $\pm$ 0.5
C	2.1 $\pm$ 0.5
D	1.2 typ.
E	3.6
F	1.7
G	0.8

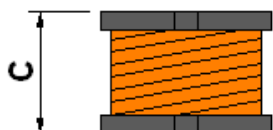

PCB PATTERN

