



Mounting in boxes

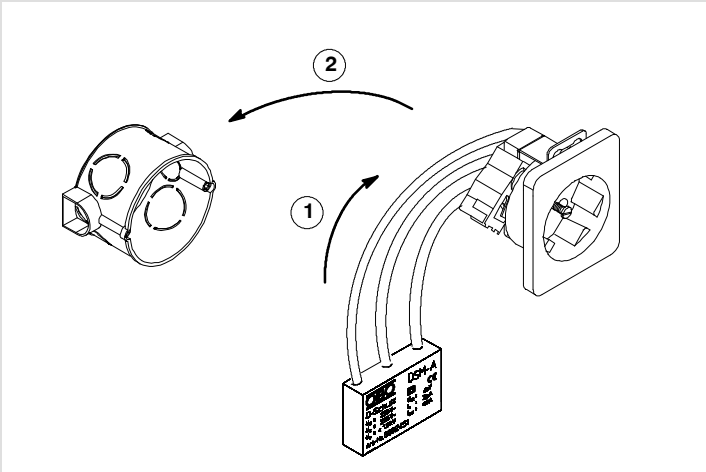

Mounting in underfloor-boxes

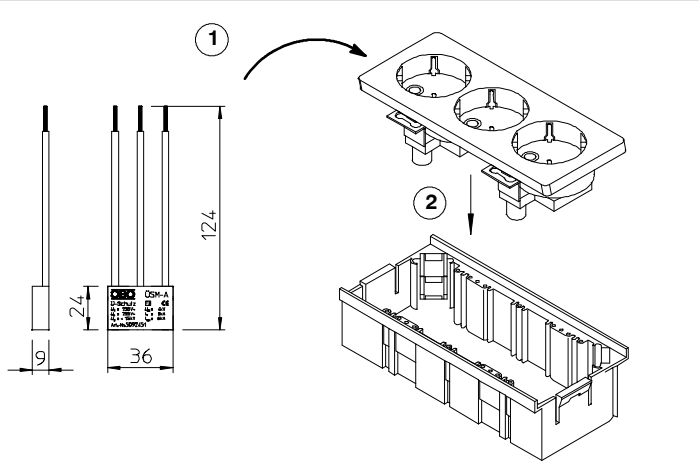

Technical Data / Technische Daten


Typ	ÜSM-A-150
U _c	170 V ~
LPZ	LPZ 2 -> 3
U _{oc}	6 kV
I _n	3 kA
I _{total} (8/20)	6 kA
max.	16 A
U _p L-N	< 1,5 kV
U _p L/N-PE	< 1,5 kV
U °C	- 15 °C - + 60 °C

E DIN VDE 0675-6 (A1/A2)
IEC 61643-1
EN 61643-11


Anforderungskategorie **D**
class **III**
Type **3**

Typ **3** EN 61643-11

LPZ **2→3** IEC 62305
DIN EN 62305

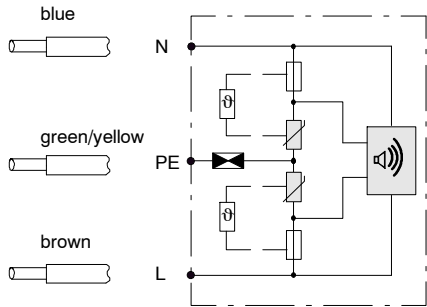

Indication

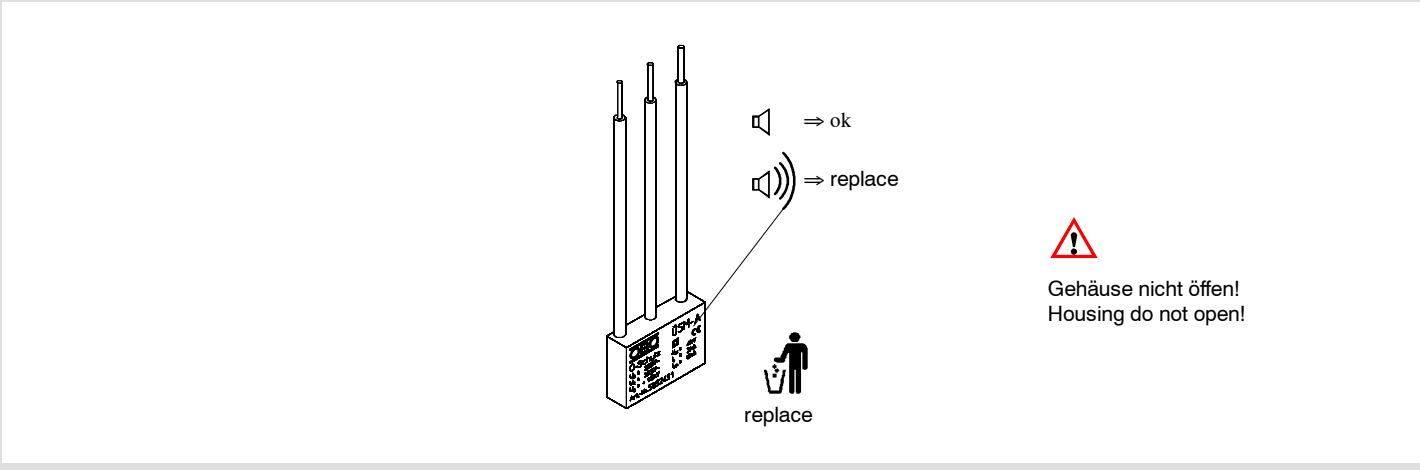

Head Office OBO BETTERMANN GmbH & Co. KG
Postfach 1120 · 58694 Menden, Germany
Hüingser Ring 52 · D-58710 Menden
Tel. +49 (0)2373-89-0 Fax +49 (0)2373-89-238 E-Mail: info@obo.de · www.obo-bettermann.com

Technical Hotline
Telefon +49 (0)2373/89-1500
Telefax +49 (0)2373/89-1550
E-Mail: hotline@obo.de