


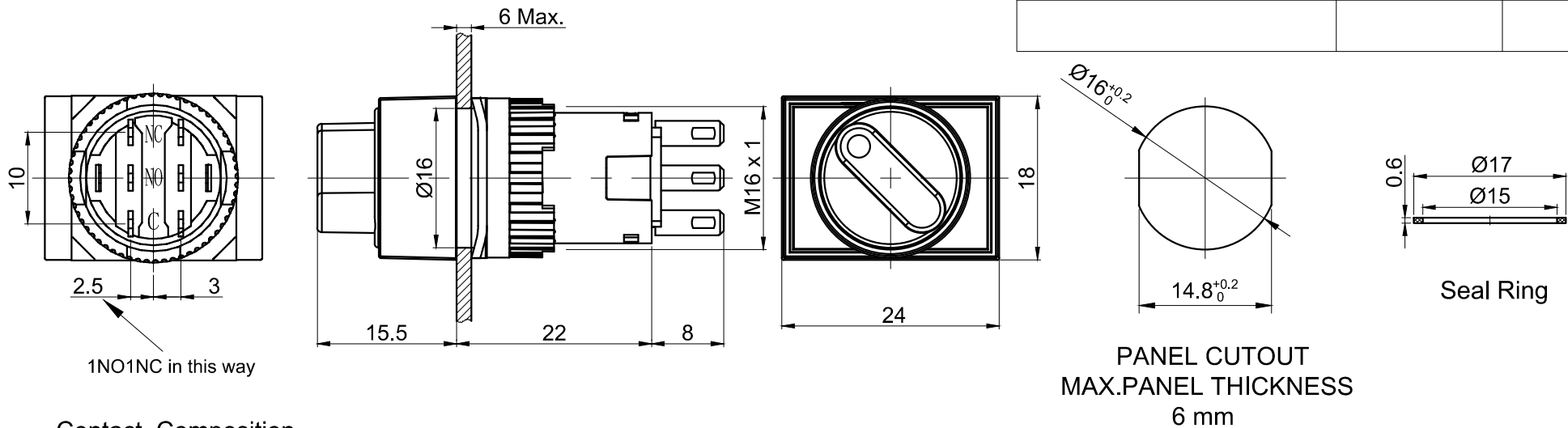

Contact Composition

Operation Position	Switch Type	90° Two Position			
		1NO1NC	2NO2NC		
⬆		NO ● NC C	NO ● NC Left C	NO ● NC C Right	
⬆		NO ● NC C	NO ● NC Left C	NO ● NC C Right	

Part Number:LAS1-AJ-□X/◇◆/△/◎

"□"	Contact structure
11	1NO 1NC
22	2NO 2NC

"◇"	Operation position
2	Two Position 
"◆"	Operation type
1	Maintain 
3	Return 

"△"	Cap Color
R	Red
G	Green
Y	Yellow

"◎"	IP class
No Letter	IP40
P	IP65

SPECIFICATIONS:

- Switch Rating: AC220V/0.5A, DC110V/0.1A.
- Mechanical Life: ≥200,000cycles.
- Electrical Life: ≥50,000cycles.
- Contact Resistance: ≤50mΩ.
- Insulation Resistance: ≥100MΩ.
- Dielectric Strength:
Between terminals of the same pole: AC 1,500V, RMS 50Hz, 1min;
Between terminals of different pole: AC 2,000V, RMS 50Hz, 1min.
- Operating Temperature: -25℃~ +55℃(No Freezing).
- IP Class: IP40,IP65(Maintain can made to order).
- Terminal Type: Pin Terminal(2.8 x 0.5mm).

MATERIALS:

- Contact: Silver alloy.
- Head: PC.
- Body: PC.
- Base: PBT.

BRAND 品牌		ONPOW		红波按钮制造有限公司 ONPOW PUSH BUTTON MANUFACTURE CO.,LTD.			
THESE DRAWINGS AND SPECIFICATIONS ARE THE PROPERTY OF ONPOW PUSH BUTTON MANUFACTURE CO.,LTD. AND SHALL NOT BE REPRODUCED COPIED OR USED IN ANY MANNER WITHOUT THE PRIOR WRITTEN CONSENT OF ONPOW PUSH BUTTON MANUFACTURE CO.,LTD.				USED 用途		APPD 审核 CH 2019/06/10	
				FINISH 处理		CHKD 校对 NCH 2019/06/10	
				SCALE 比例 1.4 : 1		UNIT 单位 mm	
						DR. 制图 ZPD 2019/06/10	
DIMENSIONS		TOLERANCE		TITLE 名称 LAS1-A Series selector switch			
0.00 TO 18.00mm		±0.43mm		DWG NO. 图号 LAS1-AJ-X二位置			SIZE 图纸 A4
18.01 TO 30.00mm		±0.52mm					
30.01 TO 50.00mm		±0.62mm					
50.01 TO 80.00mm		±0.74mm					
				FILE NAME 档案名称 LAS1-A-X.DWG		SHEET 张	1 / 1
						REV. 更改	1