




DIN 7973 C

~ISO 1483

450 HV

Standard withdrawn

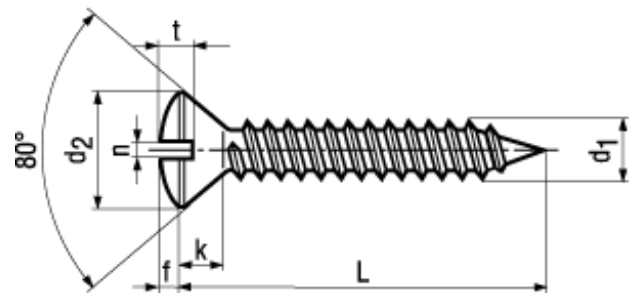

BN 991

Slotted oval countersunk head tapping screws

with cone end type C

Steel case-hardened 450 HV

zinc plated blue

- ~UNI 6953 AB
- ~ČSN 021238



ISO 4042

Quenched and tempered fasteners ≥ 360 HV and tempered case-hardened fasteners with electroplated coatings: Susceptible to hydrogen embrittlement! Further notice to residual risks can be found in the introduction section.

Article#	d ₁	d ₂ max.	f~	k~	n	t min.	L
1373765	ST 2,9	5,5	0,9	1,7	0,8	1,25	6,5
1373773							9,5
1373781							13
1373803							16
1373811							19
1373846							25
1373862	ST 3,5	6,8	1,2	2,1	1	1,55	13
1373870							16
1373889							19
1373943	(ST 3,9)	7,5	1,3	2,3	1	1,7	13
1373951							16
1373978							19
1374044	ST 4,2	8,1	1,4	2,5	1,2	1,85	13
1374052							16
1374060							19
1374087							25