


ESPE

LOW VOLTAGE DC CABLE

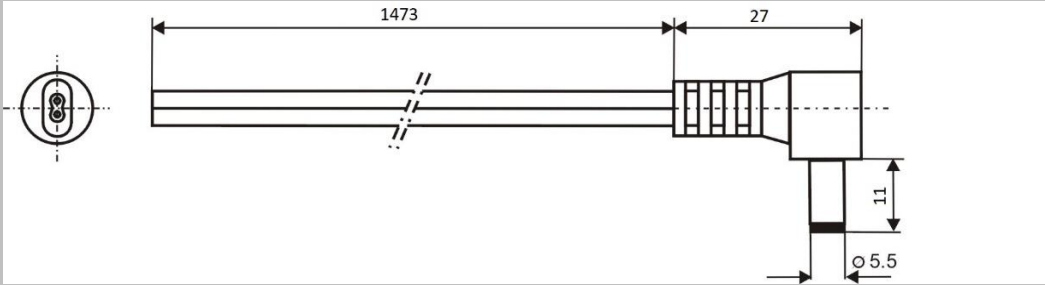

Specification:

Model	DC.CAB.2201.0150.E
DC Plug	5,5x2,1 mm
Recommended voltage	0 - 48V
Max Current	5A
Dielectric Strenght	500 VDC
Operating temperature	-20°C to +70°C
Cord Lenght	1473 mm
Cable Diameter	2x2mm
Wire Diameter	2x0,5mm ²
ROHS	+
	
Made in PRC	