




Specification:

Model	DC.CAB.2600.0025.E
DC Plug	5,5x2,5 mm
Recommended voltage	0 - 48V
Max Current	5A
Dielectric Strenght	500 VDC
Operating temperature	-20°C to +70°C
Cord Lenght	212 mm
Cable Diameter	2x2mm
Wire Diameter	2x0,5mm ²
ROHS	+

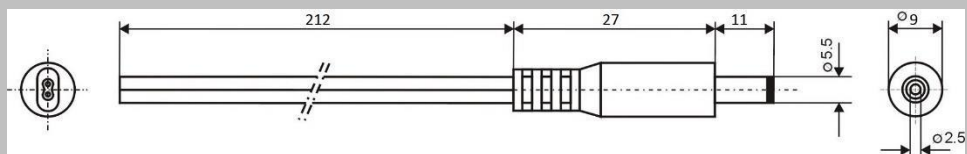

Made in PRC

