


ESPE

LOW VOLTAGE DC CABLE



Specification:

Model	DC.INV.0200.0200E
DC Plug	5,5x2,1mm (center positive)
DC Socket	5,5x2,1mm (center positive)
Recommended voltage	0 - 48V
Max Current	5A
Dielectric Strenght	500 VDC
Operating temperature	-20°C to +70°C
Cord Lenght	1960mm
Cable Diameter	2x2mm
Wire Diameter	2x0,5mm ²
ROHS	+

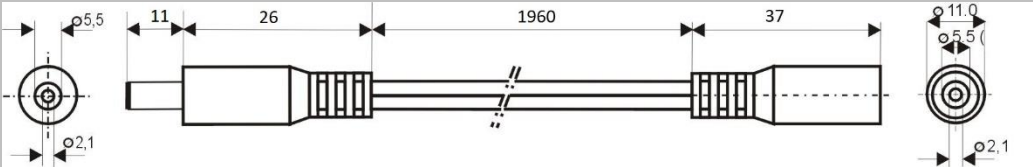

Made in PRC