


	DIN 7976 C	~ISO 1479		450 HV
---	-------------------	------------------	--	---------------

Standard withdrawn

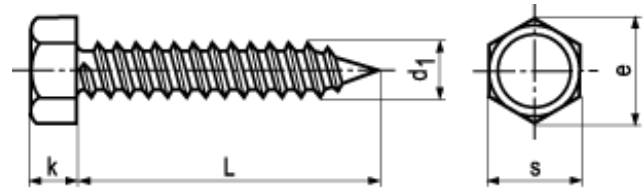

BN 2707

Hex head tapping screws

with cone end type C

Steel case-hardened 450 HV

zinc plated blue

- ~UNI 6949 AB



ISO 4042

Quenched and tempered fasteners ≥ 360 HV and tempered case-hardened fasteners with electroplated coatings: Susceptible to hydrogen embrittlement!
Further notice to residual risks can be found in the introduction section.

Article#	d ₁	k	e min.	s	L
1472461	ST 3,5	2,3	5,96	5,5	6,5
1472488					9,5
1472496					13
1472518					16
1472526					19
1472623	ST 4,2	2,8	7,59	7	9,5
1472631					13
1472658					16
1472666					19
1472682					25
1472690					32
1472704	ST 4,8	3	8,71	8	9,5
1472712					13
1472720					16
1472739					19
1472747					22
1472755					25
1472763					32
1472771					38
1472798					45
1472801	(ST 5,5)	4	8,71	8	13
1472828					16
1472836					19
1472844					22
1472852					25
1472860					32
5503934					38

Article#	d ₁	k	e min.	s	L
1472887	(ST 5,5)	4	8,71	8	45
1472895					50
1472909	ST 6,3	4,8	10,95	10	13
1472917					16
1472925					19
1472933					22
1472941					25
1472968					32
1472976					38
1472984					45
1472992					50