




DIN 7513 B

450 HV

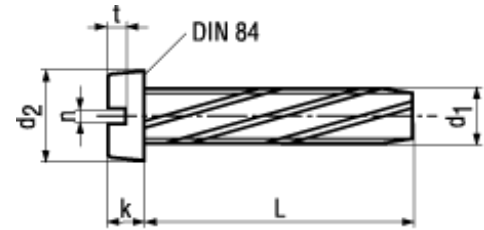

BN 1013

Slotted cheese head thread cutting screws

type B, with metric thread

Steel case-hardened 450 HV

zinc plated blue



ISO 4042

Quenched and tempered fasteners ≥ 360 HV and tempered case-hardened fasteners with electroplated coatings: Susceptible to hydrogen embrittlement!
Further notice to residual risks can be found in the introduction section.


[3D Cadenas](#)


Application: Light metal, non-ferrous metal, aluminum die-casting, zinc die-casting, gray cast iron

Article#	d ₁	d ₂ max.	k	n	t min.	Bore Ø H11	L
1380621	M2,5	4,5	1,6	0,6	0,7	2,2	6
1380648							8
1380699	M3	5,5	2	0,8	0,85	2,7	6
1380710							10
1380729							12
1380737							16
1380753							25
1380796	M4	7	2,6	1,2	1,1	3,6	10
1380818							12
1380834							20
1380842							25
1380877	M5	8,5	3,3	1,2	1,3	4,5	10
1380966	M6	10	3,9	1,6	1,6	5,5	16