



Electric Components > Products > Circular connectors > M23 Power > M23 Power INOX housing > M23 Power INOX cable connector > [M23 Power INOX cable connector](#)


7.554.500.000 M23 Power INOX cable connector

Cable diameter	7 – 12 mm
Material housing	Stainless steel 1.4404 (AISI 316)
Material seals/o-rings	FKM (FPM)
Protection class	IP 67, IP 69 K
Temperature range	-40°C to +125°C

- // [Housing without contact inserts](#)
- // [Electrical data depend on the contact insert](#)
- // [M23 Power Inserts](#)
- // [M23 Power Contacts](#)
- // [M23 Power Accessories](#)
- // You can find further information in the [Technology Center](#)

Additional information

- // [Assembly instruction INOX cable connector](#)
- // [Applications and References Product Video](#)
- // [Application report M23 Power INOX](#)
- // [Note on storage of articles with elastomer components \(circular connectors\)](#)

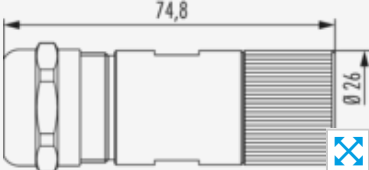

Certificates for download

