




DIN 427

~ISO 2342

14 H / 22 H

Norm zurückgezogen

Nach Wahl des Herstellers

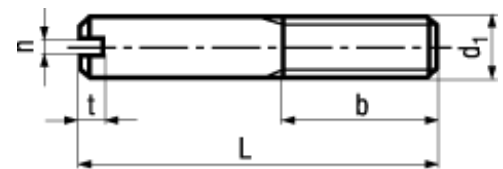

## BN 433

### Schaftschrauben

mit Schlitz und Kegelkuppe

Stahl 14 H / 22 H

verzinkt-blau



Gewindestifte sind nicht für die Anwendung unter Zugbelastung vorgesehen.



[3D Cadenas](#)

| Article# | d <sub>1</sub> | b   | n   | t min. | L    |
|----------|----------------|-----|-----|--------|------|
| 1182900  | M3             | 3,6 | 0,4 | 0,8    | 6    |
| 1182919  |                |     |     |        | 8    |
| 1182927  |                |     |     |        | 10   |
| 1182935  |                |     |     |        | 12   |
| 1182943  |                |     |     |        | 16   |
| 1182951  |                |     |     |        | (18) |
| 1182978  |                |     |     |        | 20   |
| 1182986  | M4             | 4,8 | 0,6 | 1,12   | 8    |
| 1182994  |                |     |     |        | 10   |
| 1183001  |                |     |     |        | 12   |
| 1183028  |                |     |     |        | 16   |
| 1183036  |                |     |     |        | (18) |
| 1183044  |                |     |     |        | 20   |
| 1436759  |                |     |     |        | 25   |
| 1447270  |                |     |     |        | 30   |
| 1183060  | M5             | 6   | 0,8 | 1,28   | 10   |
| 1183079  |                |     |     |        | 12   |
| 1183087  |                |     |     |        | 16   |
| 1183095  |                |     |     |        | (18) |
| 1183109  |                |     |     |        | 20   |
| 1183125  |                |     |     |        | 25   |
| 1447289  |                |     |     |        | 30   |
| 1183133  | M6             | 7,2 | 1   | 1,6    | 10   |
| 1183141  |                |     |     |        | 12   |
| 1183168  |                |     |     |        | 16   |
| 1183176  |                |     |     |        | 20   |
| 1183192  |                |     |     |        | 25   |

| Article# | d <sub>1</sub> | b   | n   | t min. | L  |
|----------|----------------|-----|-----|--------|----|
| 1183206  | M6             | 7,2 | 1   | 1,6    | 30 |
| 1183214  |                |     |     |        | 35 |
| 1183222  |                |     |     |        | 40 |
| 1302019  |                |     |     |        | 50 |
| 1447297  |                |     |     |        | 60 |
| 1183230  | M8             | 9,6 | 1,2 | 2      | 16 |
| 1267159  |                |     |     |        | 20 |
| 1183249  |                |     |     |        | 25 |
| 1183257  |                |     |     |        | 30 |
| 1183265  |                |     |     |        | 35 |
| 1183273  |                |     |     |        | 40 |
| 1436767  |                |     |     |        | 45 |
| 1183281  |                |     |     |        | 50 |
| 1315854  |                |     |     |        | 60 |
| 1419250  | M10            | 12  | 1,6 | 2,4    | 20 |
| 1419269  |                |     |     |        | 25 |
| 1419277  |                |     |     |        | 30 |
| 1419285  |                |     |     |        | 35 |
| 1419293  |                |     |     |        | 40 |
| 1419307  |                |     |     |        | 45 |
| 1419315  |                |     |     |        | 50 |
| 1419323  |                |     |     |        | 60 |
| 1419331  | M12            | 14  | 2   | 2,8    | 25 |
| 1419358  |                |     |     |        | 30 |
| 1419366  |                |     |     |        | 40 |