



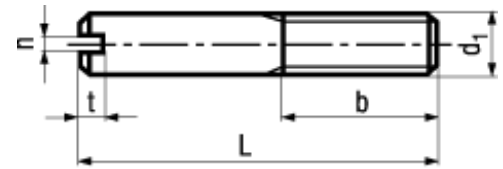
DIN 427

~ISO 2342

14 H / 22 H

Standard withdrawn

At manufacturer's option

**BN 433****Slotted set screws partially threaded**

with chamfered end

Steel 14 H / 22 H

zinc plated blue



Set screws are not intended to be tensile-loaded.

Article#	d ₁	b	n	t min.	L
1182900	M3	3,6	0,4	0,8	6
1182919					8
1182927					10
1182935					12
1182943					16
1182951					(18)
1182978					20
1182986	M4	4,8	0,6	1,12	8
1182994					10
1183001					12
1183028					16
1183036					(18)
1183044					20
1436759					25
1447270					30
1183060	M5	6	0,8	1,28	10
1183079					12
1183087					16
1183095					(18)
1183109					20
1183125					25
1447289					30
1183133	M6	7,2	1	1,6	10
1183141					12
1183168					16
1183176					20
1183192					25

Article#	d ₁	b	n	t min.	L
1183206	M6	7,2	1	1,6	30
1183214					35
1183222					40
1302019					50
1447297					60
1183230	M8	9,6	1,2	2	16
1267159					20
1183249					25
1183257					30
1183265					35
1183273					40
1436767					45
1183281					50
1315854					60
1419250	M10	12	1,6	2,4	20
1419269					25
1419277					30
1419285					35
1419293					40
1419307					45
1419315					50
1419323					60
1419331	M12	14	2	2,8	25
1419358					30
1419366					40