

## „Shark“ Plug 32A 3P+Z+N 400V IP67

Cat. No. 0252-6




- with screw terminals
- housing material: PA6
- contacts: brass
- to order nickel-plated contacts please add a „v“ e.g. 0252-6v

IP67 watertight

Connection  
to the future

### Dimensions:

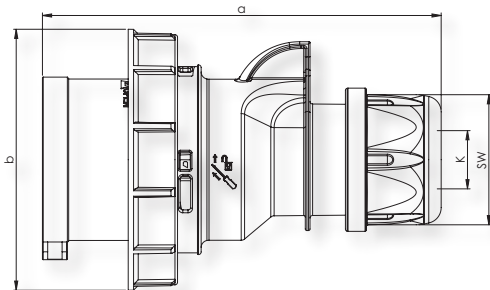

|                                  | 32 Amp         |         |         |
|----------------------------------|----------------|---------|---------|
| Poles                            | 3              | 4       | 5       |
| a                                | 150            | 150     | 155     |
| b                                | 93             | 93      | 100     |
| K_cable Ø [mm]                   | 11,5-20        | 11,5-20 | 11,5-22 |
| Connection type:                 | Screw terminal |         |         |
| Wire flexible [mm <sup>2</sup> ] | 2,5-6          |         |         |
| Contact screws [Ncm]             | 110 Ncm        |         |         |
| SW                               | 50             | 50      | 50      |
| Weight [g]                       | 223            | 242     | 276     |

**PCE Polska Sp. z o. o.**

ul. Podwalna 8A  
58-200 Dzierżonów  
TEL. +48 74 831 76 00  
FAX. + 48 74 831 17 00  
MAIL: pce@pce.pl  
www.pce.pl