

Features:

- 2 ~ 12 circuits available

Specification:

- Current rating and wire size:

Wire Size AWG	Circuits			
	2, 3	4 ~ 6	7 ~ 10	11, 12
# 16	9 A	8 A	7 A	6 A
# 18	9 A	8 A	7 A	6 A
# 20	7 A	6 A	5 A	5 A
# 22	5 A	4 A	4 A	4 A
# 24	4 A	3 A	3 A	3 A
# 26	3 A	2 A	2 A	2 A
# 28	2 A	1 A	1 A	1 A

- Voltage rating: 600V (R.M.S.)
- Insulation resistance: DC 500V 1000M Ω min.
- Dielectric withstanding voltage: 1500V AC/minute
- Ambient temperature range: -25°C ~ 85°C
(including temperature rise)

Dimensional Information (mm)


Circuits	Dim. A	Dim. B	Dim. C
N	4.2 x (N - 1)	4.2 x N + 1.2	4.2 x N + 6.6

&& N = 2 ~ 12

Ordering Information

Part No.	Material	Feature
H5050-XXPSWA00R	UL 94V-2	Without Mtg. Ears
H5050-XXPSW000R		With Mtg. Ears
H5050-XXPSWA01R	UL 94V-0	Without Mtg. Ears
H5050-XXPSW001R		With Mtg. Ears

&& xx = 02 ~ 12

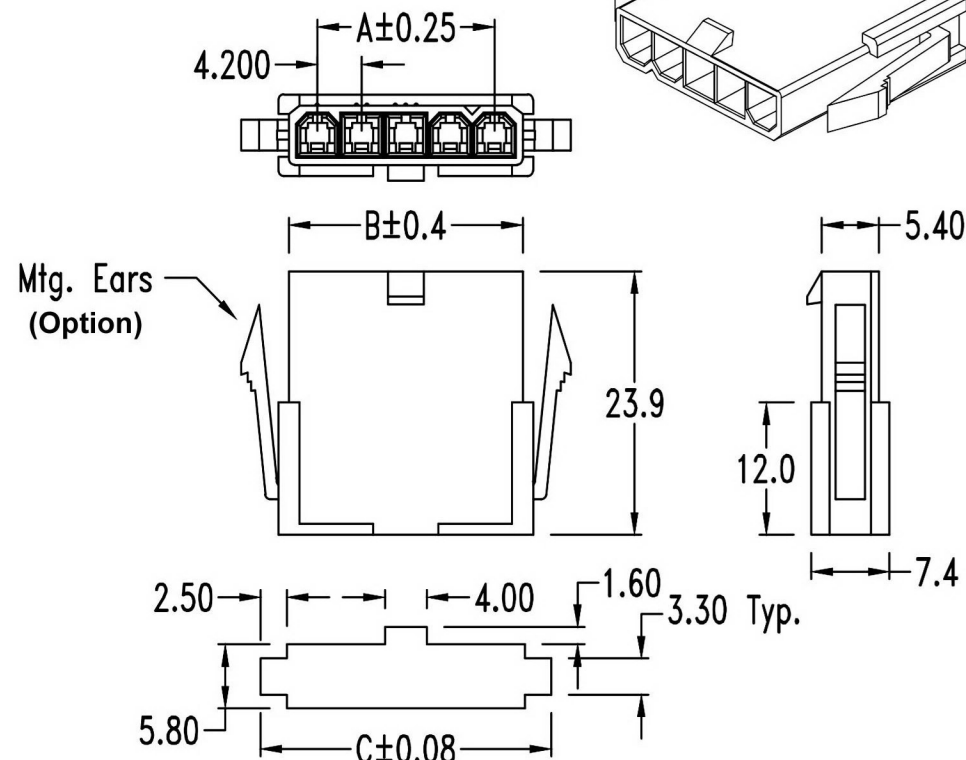

PANEL CUTOUT [Max. panel thickness: .079" (2.0mm)]

RoHS Compliant		HSM 玄茂科技股份有限公司 HSUAN MAO TECHNOLOGY CO., LTD.	
APPD. 核准 HELEN	SCALE 比例 參考	TOLERANCE .000 ± 0.08 (mm) .00 ± 0.25 (mm) .0 ± 0.40 (mm)	PART NAME 品名 MINI FIT 4.2mm FEMALE HOUSING 1XXXP ROHS
DWG. 製圖 ABBY	UNIT 單位 MM	SIZE. 紙張尺寸 A 4	PART NO. 料號 H5050-XXPSWX0XR
DATE 制表日 2020/07/29	PAGE 張數 1 OF 1	REV. 版次 C	