
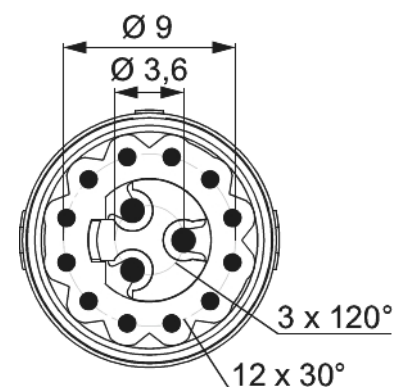


Contact insert M16 - 15-pole

Itemnumber 7003985102

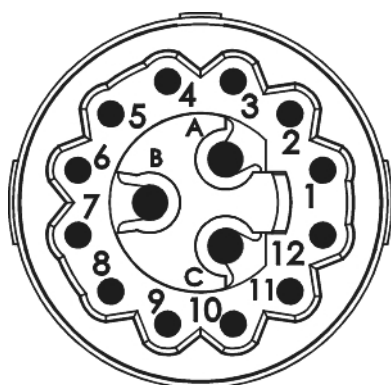

Technical data

Characteristic of connection	Crimp
Number of poles	15
Pole picture	12 + 3
Insert	Socket
colour	white
Material insulating body	PA 6, PBT
Number of contacts signal	12
Number of contacts power	3
Contact-Ø signal	0,8 mm
Contact-Ø power	1,25 mm
Terminal cross section signal	0.08 – 0.34 mm ²
Terminal cross section power	0.5 – 1,5 mm ²
Nominal current signal	3 A
Nominal current power	10 A
Nominal voltage at degree of pollution 3 signal	24 V~

Contact insert M16 - 15-pole

Itemnumber 7003985102

Nominal voltage at degree of pollution 3 power	60 V~
Test voltage signal	500 V~
Test voltage power	1500 V~
Insulation resistance signal	$> 10^{10}$ Ohm
Max. contact resistance signal	3 Ohm
Temperature range	-40°C to +125°C
Degree of Protection	3
Flammability	V-0 (UL 94)
Suitable crimping tool	7000900904

Contact insert M16 - 15-pole

Itemnumber 7003985102

Commercial data

Packaging Unit	10
EAN code	4033878501597
Weight	0.002 kg
ETIM 7	EC003557
eCl@ss 10.1	27440223

Note: