




DIN 85 A

~ISO 1580

8.8

Standard withdrawn

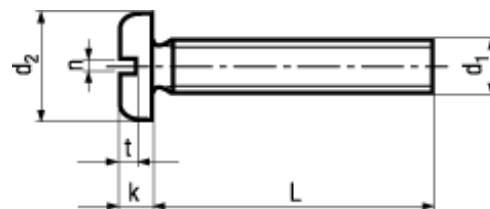

BN 351

Slotted pan head machine screws

Steel 8.8

zinc plated blue

- ~UNI 6108
- ~ČSN 021137

 [3D Cadenas](#)
 All lengths fully threaded

M2,5: in accordance with ISO 1580

Article#	d ₁	d ₂	k max.	n	t min.	L
1134051	M2,5	5	1,5	0,6	0,6	4
1134078						5
1134086						6
1134094						8
1134108						10
1134116						12
3056162	M3	6	1,8	0,8	0,7	4
1134361						5
1134388						6
1134396						8
1134418						10
1134426						12
1134442						16
1134469						20
1134485						25
3056163	M4	8	2,4	1,2	1	5
1134698						6
1134701						8
1134728						10
1134736						12
1134752						16
1134779						20
1134795						25
1134817						30
1134833						40
1134884	M5	10	3	1,2	1,2	6

M2,5: in accordance with ISO 1580

Article#	d ₁	d ₂	k max.	n	t min.	L
1134892	M5	10	3	1,2	1,2	8
1134906						10
1134914						12
1134930						16
1134957						20
1134973						25
1135007						30
1135023						40
3056165	M6	12	3,6	1,6	1,4	8
1135090						10
1135104						12
1135120						16
1135147						20
1135163						25
1135198						30