




DIN 85 A

~ISO 1580

4.8

Norm zurückgezogen

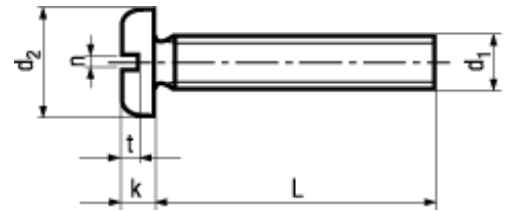

BN 1362

Flachkopfschrauben Pan-Head

mit Schlitz

Stahl 4.8

blank

- ~UNI 6108
- ~ČSN 021137



3D Cadenas



Alle Längen Gewinde ~ bis Kopf

M2,5: nach ISO 1580

Article#	d ₁	d ₂	k max.	n	t min.	L
1135899	M2,5	5	1,5	0,6	0,6	3
1135902						4
1135910						5
1135929						6
1135937						8
1135945						10
1136011	M3	6	1,8	0,8	0,7	4
1136038						5
1136046						6
1136054						8
1136062						10
1136070						12
1136097						16
1136100						20
1136151	M4	8	2,4	1,2	1	6
1136178						8
1136186						10
1136194						12
1136216						16
1136224						20
1136283	M5	10	3	1,2	1,2	8
1136291						10
1136305						12
1136321						16
1136348						20
1136410	M6	12	3,6	1,6	1,4	8

M2,5: nach ISO 1580

Article#	d ₁	d ₂	k max.	n	t min.	L
1136429	M6	12	3,6	1,6	1,4	10
1139363						12
1136437						(14)
1136445						16
1136453						20
1136461						25