




DIN 966 A

~ISO 7047

4.8

Norm zurückgezogen

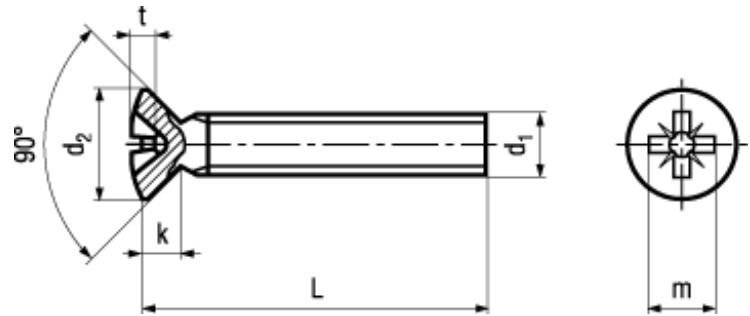

BN 14068

Linsensenkschrauben

mit Kreuzschlitz Pozidriv Form Z

Stahl 4.8

verzinkt-blau

- ~UNI 7689
- ~ČSN 021156

3D Cadenas

Alle Längen Gewinde ~ bis Kopf

Article#	d ₁	d ₂ max.	k max.		m~	t min.	t max.	L
2099241	M2,5	4,7	1,5	1	2,8	1,5	1,75	5
2099268								6
2099276								8
2099284								10
2099292								12
2099306	M3	5,6	1,65	1	3,1	1,83	2,08	5
2099314								6
2099322								8
2099330								10
2099349								12
2099357								16
2099365	M4	7,5	2,2	2	4,6	2,26	2,72	6
2099373								8
2099381								10
2099403								12
2099411								16
2099438								20
2099446								25
2099454								30
2099462								40
2099470	M5	9,2	2,5	2	5,3	2,89	3,35	8
2099489								10
2099497								12
2099500								16
2099519								20
2099527								25

Article#	d ₁	d ₂ max.	k max.		m~	t min.	t max.	L
2099535	M5	9,2	2,5	2	5,3	2,89	3,35	30
2099543								40
2099551	M6	11	3	3	7	3,3	3,76	10
2099578								12
2099586								16
2099594								20
2099608								25
2099616								30
2099624								35
2099632								40