




Material	Zinc die casting / Nickel plated brass
Clamping insert	Polyamide
Seal ring	Buna-N
O-Ring	Buna-N
Protection	IP 68
Operating Temperature	-40 °C – 100 °C (-40 °F – 212 °F)


// Other sealing materials e.g. silicone upon request



with mounting flange

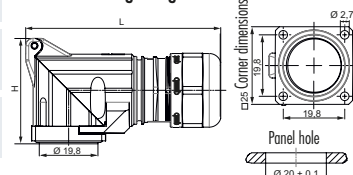

with threaded connection

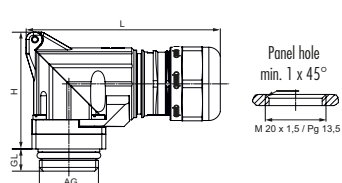

AG	Ø mm	GL mm	H mm	L mm	R mm	mm	Number
with mounting flange							
	10–14		29	66	7	25	1.309.2000.50
	7–12		29	66	7	25	1.309.2000.51
with threaded connection							
M 20 x 1,5	10–14	6	37	66	7	25	1.309.2020.50
	7–12	6	37	66	7	25	1.309.2020.51
PG 13,5	10–14	6	37	66	7	25	1.309.2013.50
	7–12	6	37	66	7	25	1.309.2013.51